




Heat Shrink Female Quick Disconnect For 16 - 14 AWG (.25 x .03)

By Burndy
Catalog # [YHSQ14F25X03](#)

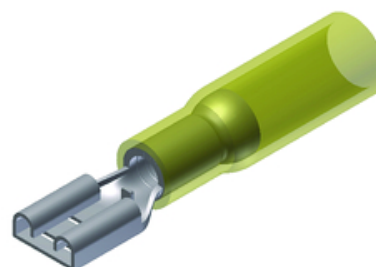

Cu Heat Shrink Insul Female Quick Disconnect, 14-16 AWG, 1.42" L, 0.25" W, Serrated bbl, Tin plated, Blue(Insul Color).

Application

For Use On Copper Conductor

General

Catalog Number	YHSQ14F25X03
Connector Type	Female Quick Disconnect
EU RoHS Indicator	Yes
Insulation	Y
Insulation Type	Heat Shrink
Material	Copper
Plated	Y
Plating Type	Tin
Sub Brand	HYDENT
Trade Name	HYDENT™
Type	YHS
UPC	781810477106

Dimensions

Dimension - B Length fraction	2/9 in
Dimension - B Length inch	0.22 in
Dimension - L Length Overall mm	32 mm
Dimension - Length Overall inch	1.27 in
Dimension - Pad Width inch	0.30 in
Dimension - Strip Length inch	5/16

Conductor Related

Conductor - Copper Solid Size	16 AWG;15 AWG;14 AWG
Conductor - Copper Solid Size Range	16 AWG-14 AWG
Conductor - Copper Str Size	16 AWG;14 AWG
Conductor - Copper Str Size Range	16 AWG - 14 AWG
Conductor Size	16 - 14 AWG
Conductor Type	• CU C Solid-Size • CU C Str-Size

Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	No

Logistics

Carton Quantity	1200
Packaging Type	Bag
Pallet Quantity	99999

Product Assets

[3D Models - YHSQ14F25X03_MODEL-PDF](#)
[3D Models - YHSQ14F25X03_MODEL-STEP](#)
[3D Models - YHSQ14F25X03_MODEL-IGES](#)
[Catalogs - Full Line BURNDY Catalog](#)
[Catalogs - Section B - Small Compression](#)
[Product Cross Section Image\(s\) - BUR_YHSQ18F25X03_LineArt](#)
[Sales Drawings - 50094214](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.
BRDY_CA-YHSQ14F25X03-SPEC-EN | REV 6/2024