



YHSS10, Heat Shrink Splice For 12 - 10 AWG

By Burndy
Catalog # YHSS10

Heat Shrink Splice For 12 - 10 AWG.

Features

- Made from pure copper, annealed for maximum strength
- Color-coded, imprinted with wire size
- Serrated barrels offer maximum wire contact and tensile strength
- Electro-tin plated for corrosion resistance

Application


For Use On Copper Conductor

General

Catalog Number	YHSS10
Connector Type	Seamless Butt Splice
EU RoHS Indicator	Yes
Insulation	Y
Insulation Type	Heat Shrink
Material	Copper
Plated	Y
Plating Type	Tin
Sub Brand	HYDENT
Trade Name	HYDENT™
Type	YHS, Heat Shrink
UPC	781810476918
UPC 14 Digit GTIN	00781810476918

Dimensions

Dimension - B Length fraction	1/4 in
Dimension - B Length inch	0.25 in
Dimension - L Length Overall mm	41 mm
Dimension - Length Overall inch	1.60 in

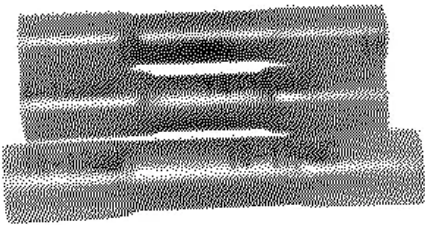

Dimension - Strip Length inch 5/16

Conductor Related

Conductor - Copper Solid Size	12 AWG;11 AWG;10 AWG
Conductor - Copper Solid Size Range	12 AWG-10 AWG
Conductor - Copper Str Size	12 AWG;10 AWG
Conductor - Copper Str Size Range	12 AWG-10 AWG
Conductor Size	12 - 10 AWG
Conductor Type	• CU C Solid-Size • CU C Str-Size

Certifications And Compliance

Standards - RoHS Compliance Status	CM
------------------------------------	----

Logistics

Carton Quantity	100
Packaging Type	Bag

Product Assets

- [3D Models - YHSS10_MODEL-PDF](#)
- [3D Models - YHSS10_MODEL-IGES](#)
- [3D Models - YHSS10_MODEL-STEP](#)
- [Catalogs - BURNDY Master Catalog - Section B - Small Terminals](#)
- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Product Cross Section Image\(s\) - BUR_YHSS18_LineArt](#)
- [Sales Drawings - 50094203](#)
- [Specifications - YHSS10 Specification Sheet English](#)
- [Specifications - YHSS10 Specification Sheet French](#)