

YP29C26, Figure 6-shaped Copper Tap Connector

By Burndy
Catalog # [YP29C26](#)

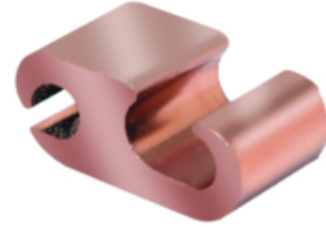


Figure 6 - shaped, wide range-taking CU compression tap connector for primary service taps and secondary service drops, Width: .75 IN, Die Index: D.

Application

For Extra Wide Range Of Copper And Primary Service Taps And Secondary Service Drops

General

Catalog Number	YP29C26
Connector Type	Tap
Die Index	D
EU RoHS Indicator	Yes
Material	Copper
Plated	Y
Plating Type	Unplated
Sub Brand	CRIMPIT
Trade Name	CRIMPIT™
Type	YP-C
UPC	781810118009
UPC 12 Digit	7818101180099

Dimensions

Dimension - Height inch	2.00 in
Dimension - L Length Overall mm	19 mm
Dimension - Length Overall inch	1.00 in

Conductor Related

Conductor - Copper Str Run	1/0 ;2/0 AWG;3/0 AWG;4/0 AWG;250 kcmil
Conductor - Copper Str Run Range	1/0 -250 kcmil
Conductor - Copper Str Tap	4 AWG;3 AWG;2 AWG;1 AWG;1/0 ;2/0 AWG
Conductor - Copper Str Tap Range	4 AWG-2/0 AWG

Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	No

Logistics

Carton Quantity	50
Pallet Quantity	8700

Product Assets

[3D Models - YP29C26_MODEL-STEP](#)
[3D Models - YP29C26_MODEL-PDF](#)
[3D Models - YP29C26_MODEL-IGES](#)
[Catalogs - Full Line BURNDY Catalog](#)
[Catalogs - Section H - Overhead Distribution](#)
[Customer Notices - Prop 65 Notice](#)
[Product Cross Section Image\(s\) - BUR_YP-C_LineArt](#)
[Sales Drawings - SC058072-01](#)