



YP29C261, Figure 6-shaped Copper Tap Connector

By Burndy
Catalog # [YP29C261](#)

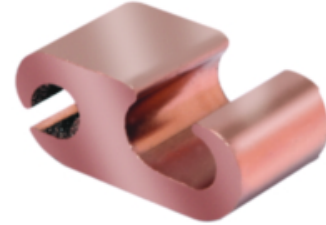


Figure 6 - shaped, wide range-taking CU compression tap connector for primary service taps and secondary service drops.

Application

Line Tap for Extra Wide Range of Copper

General

Catalog Number	YP29C261
Connector Type	Tap
EU RoHS Indicator	Yes
Material	Copper
Plated	Y
Plating Type	Unplated
Sub Brand	CRIMPIT
Trade Name	CRIMPIT™
Type	Overhead Bare Connectors
UPC	781810461822
UPC 12 Digit	7818104618222

Dimensions

Dimension - Height inch	2.00 in
Dimension - L Length Overall mm	25 mm
Dimension - Length Overall inch	1.00 in

Conductor Related

Conductor - Copper Str Run	1/0 ;2/0 AWG;3/0 AWG;4/0 AWG;250 kcmil
Conductor - Copper Str Run Range	1/0 AWG-250 kcmil
Conductor - Copper Str Tap	4 AWG;3 AWG;2 AWG;1 AWG;1/0 ;2/0 AWG
Conductor - Copper Str Tap Range	4 AWG-2/0 AWG

Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	No

Logistics

Carton Quantity	50
Pallet Quantity	8700

Product Assets

[Catalogs - Full Line BURNDY Catalog](#)
[Customer Notices - Prop 65 Notice](#)
[Product Cross Section Image\(s\) - BUR_YP-C_LineArt](#)
[Sales Drawings - SC058072-01](#)



A proud member of the Hubbell Family.