


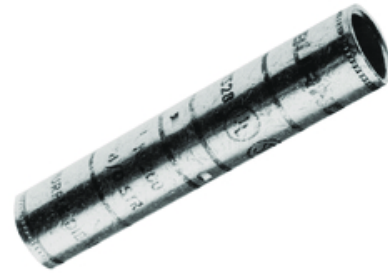

YS27, Cu Compression Splice, Long Barrel, 3/0 AWG

By Burndy
Catalog # [YS27](#)

3/0 AWG CU, Long Barrel, Internal Chamfer, Tin Plated,
UL/CSA, 90°C, Up to 35kV, ORANGE Color Code, 14 Die Index.



Application

Wire Splice

General

Catalog Number	YS27
Color Code	Orange
Connector Type	LONG BARREL
Die Index	14
EU RoHS Indicator	Yes
Feature - Barrel Style	Chamfered
Feature - Barrel Type	Long
Finish Type	Tin-Plated
Material	COPPER
Plated	Y
Plating Type	Tin - Electro Plated
Sub Brand	HYLINK
Trade Name	HYLINK™
Type	YS, Long Barrel
UPC	781810507704
UPC 12 Digit	7818105077044

Dimensions

Dimension - B Length inch	1.45 in
Dimension - L Length Overall mm	84 mm
Dimension - Length Overall inch	3.30 in
Dimension - Strip Length inch	1-1/2

Electrical Ratings

Voltage - Maximum	35000
Voltage Rating	35 kV

Conductor Related

Conductor - Copper Str Navy Size	150 (61) Navy
Conductor - Copper Str Size	1000 KCMIL
Conductor - Copper Str Size Range	3/0 AWG
Conductor - Material	COPPER
Conductor Size	3/0 AWG
Conductor Type	CODE
Wire Size	1000 KCMIL

Certifications And Compliance

Certification - CSA Approved	Yes
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	UL 486A-486B
Standards - Industry Standards Met	UL 486A-486B
Standards - RoHS Compliance Status	CM
UL Listed	Yes

Logistics

Carton Quantity	10
-----------------	----

Product Assets

[3D Models - YS27_MODEL-PDF](#)
[3D Models - YS27_MODEL-STEP](#)
[3D Models - YS27_MODEL-IGES](#)
[Catalogs - Full Line BURNDY Catalog](#)
[Catalogs - Section C - Compression Connections](#)
[Customer Notices - Prop 65 Notice](#)
[Sales Drawings - SD007774-01](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.
BRDY_CA-YS27-SPEC-EN | REV 6/2024