


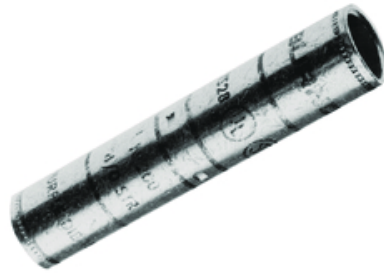

YS6C, Cu Compression Splice, Long Barrel, 6 AWG

By Burndy
Catalog # [YS6C](#)

6 AWG CU, Long Barrel, Internal Chamfer, Tin Plated, UL/CSA,
90°C, Up to 35kV, BLUE Color Code, 7 or 374 Die Index.



Application

Wire Splice

General

Catalog Number	YS6C
Color Code	Blue
Connector Type	LONG BARREL
Die Index	7
EU RoHS Indicator	Yes
Feature - Barrel Style	Chamfered
Feature - Barrel Type	Long
Finish Type	Tin-Plated
Material	COPPER
Plated	Y
Plating Type	Tin - Electro Plated
Sub Brand	HYLINK
Trade Name	HYLINK™
Type	YS, Long Barrel
UPC	781810507407
UPC 12 Digit	7818105074077

Dimensions

Dimension - B Length inch	1.09 in
Dimension - L Length Overall mm	60 mm
Dimension - Length Overall inch	2.38 in
Dimension - Strip Length inch	1-3/16

Electrical Ratings

Voltage - Maximum	35000
Voltage Rating	35 kV

Conductor Related

Conductor - Copper Solid Size	6 Sol.
Conductor - Copper Str Size	6 AWG
Conductor - Copper Str Size Range	6 AWG
Conductor - Material	COPPER
Conductor Size	6 AWG
Conductor Type	CODE
Wire Size	#6 AWG

Certifications And Compliance

Certification - CSA Approved	Yes
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	UL 486A-486B
Standards - Industry Standards Met	UL 486A-486B
Standards - RoHS Compliance Status	CM
UL Listed	Yes

Logistics

Carton Quantity	50
-----------------	----

Product Assets

[3D Models - YS6C_MODEL-STEP](#)
[3D Models - YS6C_MODEL-IGES](#)
[3D Models - YS6C_MODEL-PDF](#)
[Catalogs - Full Line BURNDY Catalog](#)
[Catalogs - Section C - Compression Connections](#)
[Customer Notices - Prop 65 Notice](#)
[Sales Drawings - SD007774-01](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.
BRDY_CA-YS6C-SPEC-EN | REV 6/2024