




YSP34T, Cu Tapered End Splice, 500 kcmil

By Burndy
Catalog # [YSP34T](#)

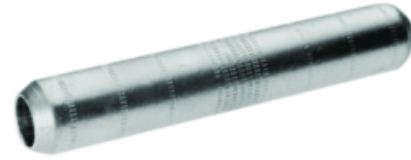

500 kcmil CU, Tapered End, Internal Chamfer, Tin Plated,
UL/CSA, 90°C, Up to 35kV, BROWN Color Code, 20 or 299 Die
Index.

Application

Wire Splice

General

| | |
|------------------------|----------------------------------|
| Catalog Number | YSP34T |
| Color Code | Brown |
| Connector Type | LONG BARREL |
| Die Index | 20 |
| EU RoHS Indicator | Yes |
| Feature - Barrel Style | Tapered |
| Feature - Barrel Type | Standard |
| Finish Type | Tin-Plated |
| Material | COPPER |
| Plated | Y |
| Plating Type | Electro Tin plated |
| Sub Brand | HYLINK |
| Trade Name | HYLINK™ |
| Type | YSP-T, High Voltage, Long Barrel |
| UPC | 781810001332 |

Dimensions

| | |
|---------------------------------|----------|
| Dimension - B Length inch | 1.71 in |
| Dimension - L Length Overall mm | 90 mm |
| Dimension - Length Overall inch | 3.55 in |
| Dimension - Strip Length inch | 1-3/4 in |

Electrical Ratings

| | |
|----------------|-------|
| Voltage Rating | 35 kV |
|----------------|-------|

Conductor Related

| | |
|-----------------------------------|-----------|
| Conductor - Copper Str Size | 500 kcmil |
| Conductor - Copper Str Size Range | 500 kcmil |
| Conductor - Material | COPPER |
| Conductor Size | 500 KCMIL |
| Conductor Type | CODE |
| Wire Size | 500 kcmil |

Certifications And Compliance

| | |
|------------------------------------|-----|
| Certification - CSA Approved | Yes |
| Certification - ETL | No |
| Standards - RoHS Compliance Status | CM |
| UL Listed | Yes |

Logistics

| | |
|-----------------|------|
| Carton Quantity | 25 |
| Pallet Quantity | 5550 |

Product Assets

[Catalogs - Full Line BURNDY Catalog](#)
[Catalogs - Section C - Compression Connections](#)
[Customer Notices - Prop 65 Notice](#)
[Sales Drawings - sc20445-01](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.
BRDY_CA-YSP34T-SPEC-EN | REV 6/2024