




CT18125C, Cable Tie, 1.25" Max Bundle, 18 Lb Tensile, Natural

By Burndy
Catalog # [CT18125C](#)

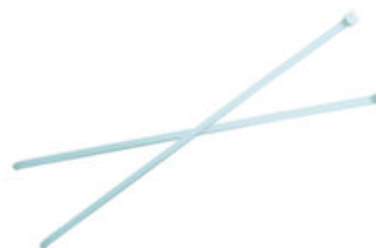

Nylon cable ties, Tensile strength-18 Lbs, Color- Natural, 6.18"L, 0.09"W, 1.50" Bundle Dia.

General

Catalog Number	CT18125C
Color	Natural
Material	NYLON 6/6
Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	-40 °C
Rating - Minimum Tensile Strength lbs	18
Tool Type	Mini
Trade Name	UNIRAP™
UPC	781810331446

Dimensions

Dimension - Bundle Diameter Max inch	1.50 in
Dimension - L Length Overall mm	157 mm
Dimension - Length Overall inch	6.18 in
Dimension - Width inch	0.09 in
Dimension - Width mm	2 mm

Certifications And Compliance

Certification - 94V0 Rated	N
Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - UV Rated	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	No

Logistics

Carton Quantity	10000
Packaging Type	Bag

Product Assets

- [3D Models - CT18125C_MODEL-PDF](#)
- [3D Models - CT18125C_MODEL-STEP](#)
- [3D Models - CT18125C_MODEL-IGES](#)
- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Catalogs - BURNDY Master Catalog - Section G - Wire Management](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Product Cross Section Image\(s\) - BUR_CT_UNIRAP_CABLE_TIE_LineArt](#)
- [Sales Drawings - 50080813](#)
- [Specifications - CT18125C](#)



A Hubbell brand