




GIE2CG3, Mechanical Grounding Connector for Flexible Rubber Sheath Cable, 6-2 AWG

By Burndy
Catalog # [GIE2CG3](#)

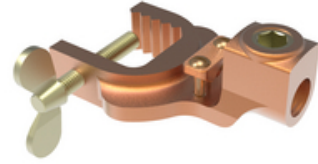

Mechanical Grounding Connector, For Flexible Rubber Sheath Cable, 6 AWG - 2 AWG.

Application

For Used To Accommodates Flexible Rubber Sheath Cable Ranging From #6 - #2 Conductors

General

Catalog Number	GIE2CG3
EU RoHS Indicator	Yes
Material	Copper Alloy, Cast
Plated	N
Plating Type	Unplated
Sub Brand	MECHANICAL CONNECTOR
Type	GIE-G
UPC	781810052297
UPC 12 Digit	7818100522977

Dimensions

Dimension - Length Overall inch	4.31 in
Dimension - Width inch	3.06 in
Dimension - Width mm	78 mm

Conductor Related

Conductor Size #6 AWG - #2 AWG

Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	EX
UL Listed	No

Product Assets

[3D Models - GIE2CG3_MODEL-IGES](#)
[3D Models - GIE2CG3_MODEL-PDF](#)
[3D Models - GIE2CG3_MODEL-STEP](#)
[Catalogs - Full Line BURNDY Catalog](#)
[Catalogs - Section E2 - Mechanical Grounding](#)
[Customer Notices - Prop 65 Notice](#)
[Product Cross Section Image\(s\) - BUR_gieg2la](#)
[Sales Drawings - 2114841](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.
BRDY_MX-GIE2CG3-SPEC-EN | REV 6/2024