




GK6429, Copper Alloy Grounding Clamp, 3 Cables to Rod or Pipe

By Burndy
Catalog # [GK6429](#)

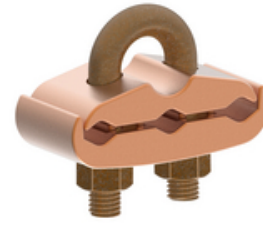

Mechanical Grounding Connector, 3 Cables to Rod or Pipe, 2/0 AWG (Sol) -250 kcmil, 3/8" Pipe, 5/8"-3/4" Rod.

Application

For Joining Three Equal Copper Cables To Rod Or Tube, Direct Burial In Earth Or Concrete

General

Catalog Number	GK6429
EU RoHS Indicator	Yes
Installation Torque Recommended in-lb	480 LBS/in
Material	Copper Alloy, Cast
Material Type - Screw Plated	DURIUM™ Silicon Bronze N
Plating Type	Unplated
Sub Brand	MECHANICAL CONNECTOR
Type	Three Cables to Rod or Tube
UPC	781810233535
UPC 12 Digit	7818102335355

Dimensions

Bolt Size	1/2 in
Dimension - B Length inch	1.63 in
Dimension - Height inch	2.88 in
Dimension - Width fraction	3-1/2 in
Dimension - Width inch	3.50 in
Dimension - Width mm	89 mm

Conductor Related

Conductor - Rod Size	5/8 in ; 3/4 in
Conductor Size	2/0 AWG Sol - 250 kcmil

Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Listed Direct Burial	Yes
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	UL467
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	EX
UL Listed	Yes

Product Assets

[3D Models - GK6429_MODEL-PDF](#)
[3D Models - GK6429_MODEL-IGES](#)
[3D Models - GK6429_MODEL-STEP](#)
[Catalogs - Full Line BURNDY Catalog](#)
[Catalogs - Section E2 - Mechanical Grounding](#)
[Customer Notices - Prop 65 Notice](#)
[Product Cross Section Image\(s\) - BUR_gk2la](#)
[Sales Drawings - sc069674-01](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.
BRDY_MX-GK6429-SPEC-EN | REV 6/2024