


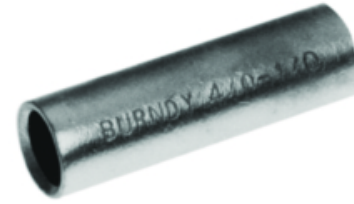

Compression Splice Reducer

By Burndy
Catalog # Y3128R

350 kcmil CU Long Barrel Size Reduced Down To 4/0 AWG Wire Size, Internal Chamfer, Tin Plated, Up to 35kV, RED Color Code, 18 or 324 Die Index.



Application

Wire Reducing Splice Adapter Insert

General

Catalog Number	Y3128R
Color Code	Red
Connector Type	LONG BARREL
Die Index	18
EU RoHS Indicator	Yes
Feature - Barrel Type	Long
Finish Type	Tin-Plated
Material	COPPER
Plated	Y
Plating Type	Tin Plated
Sub Brand	REDUCER/ADAPTER
Temperature Rating	194
Type	Y-R, Compression
UPC	781810085202
UPC 12 Digit	7818100852022

Dimensions

Dimension - B Length inch	2.00 in
Dimension - L Length Overall mm	51 mm
Dimension - Length Overall inch	2.00 in
Dimension - Outside Diameter inch	0.687 in

Electrical Ratings

Voltage - Maximum	35000
-------------------	-------

Conductor Related

Conductor - Copper Str Run	350 kcmil
Conductor - Copper Str Run Range	350 kcmil
Conductor - Copper Str Size Range	4/0 AWG
Conductor - Copper Str Tap	4/0 AWG
Conductor - Copper Str Tap Range	4/0 AWG
Conductor - Material	COPPER
Conductor Type	CODE
Wire Size	#4/0 AWG

Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	No

Logistics

Carton Quantity	100
Pallet Quantity	22200

Product Assets

[Catalogs - Full Line BURNDY Catalog](#)
[Catalogs - Section C - Compression Connections](#)
[Customer Notices - Prop 65 Notice](#)
[Sales Drawings - SD..016040-01](#)



A proud member of the Hubbell Family.