


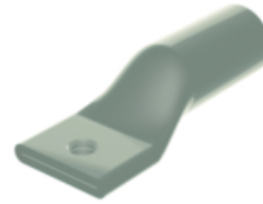

Compression Terminal

By Burndy
Catalog # YA30A7

AL Terminal, AL9CU, Internal Chamfer, Tin Plated, Prefilled PENETROX™ A13, End Cap, UL/CSA, 90°C, Up to 35kV, Color Code, Die Index.



Application

Wire Termination

General

| | |
|--------------------------------------|----------------------|
| Color Code | Blue |
| Connector Type | DUAL RATED |
| Die Index | 470 |
| Feature - Barrel Style | Chamfered |
| Feature - Barrel Type | Standard |
| Finish Type | Tin-Plated |
| Material | ALUMINUM |
| Physical Attribute - Number of Holes | 1 |
| Physical Attribute - Tongue Type | Standard |
| Plated | Y |
| Plating Type | Tin - Electro Plated |
| Temperature Rating | 194 |
| Trade Name | HYLUG™ |
| UPC | 781810033579 |
| UPC 12 Digit | 7818100335799 |

Dimensions

| | |
|-----------------------------------|-----------|
| Dimension - B Length fraction | 1-7/16 in |
| Dimension - B Length inch | 1.44 in |
| Dimension - Bolt Hole Size inch | 0.27 in |
| Dimension - Bolt Size fraction | 1/4 |
| Dimension - Bolt Size inch | 0.25 |
| Dimension - D inch | 1.37 in |
| Dimension - Hole Size fraction | 1/4 |
| Dimension - Hole Size inch | 0.27 |
| Dimension - Hole Size mm | 6.9 mm |
| Dimension - Inside Diameter inch | 0.65 in |
| Dimension - L Length Overall mm | 99 mm |
| Dimension - Length Overall inch | 3.90 in |
| Dimension - N inch | 0.63 in |
| Dimension - Outside Diameter inch | 1.01 in |
| Dimension - Pad Width inch | 1.38 in |
| Dimension - Stud Size fraction | 1/4 |
| Dimension - Thread Size | 1/4 in |
| Dimension - Z (inch) | 0.74 in |

Electrical Ratings

| | |
|-------------------|-------|
| Voltage - Maximum | 35000 |
| Voltage Rating | 35 kV |

Conductor Related

| | |
|-----------------------------------|-------------------|
| Conductor - AL Str Size | 300 KCMIL |
| Conductor - AL Str Size Range | 300 kcmil |
| Conductor - Copper Str Size | 300 KCMIL |
| Conductor - Copper Str Size Range | 300 kcmil |
| Conductor - Material | ALUMINUM / COPPER |
| Conductor Size | 300 KCMIL |
| Conductor Type | CODE |
| Wire Size | 300 KCMIL |

Certifications And Compliance

| | |
|------------------------------------|--------------|
| Certification - CSA Approved | Yes |
| Certification - ETL | No |
| Certification - UL Recognized | No |
| Certification - cULus | No |
| Industry Standard(s) | UL 486A-486B |
| Standards - Industry Standards Met | UL 486A-486B |
| Standards - RoHS Compliance Status | CM |
| UL Listed | Yes |

Logistics

| | |
|-----------------|---|
| Carton Quantity | 5 |
|-----------------|---|

Product Assets

- [Catalogs - Full Line BURNDY Catalog](#)
- [Customer Notices - Prop 65 Notice](#)
- [Installation Manuals - Aluminum Installation Instructions](#)
- [Sales Drawings - SD208046](#)

Dimension - Z (inch) 0.74 in
Physical Attribute - Tongue Straight
Angle



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.
BRDY_MX-YA30A7-SPEC-EN | REV 6/2024