


Compression Terminal

By Burndy
Catalog # [YA8CA3](#)

AL Terminal, AL9CU, Internal Chamfer, Tin Plated, Prefilled PENETROX™ A13, End Cap, UL/CSA, 90°C, Up to 35kV, Color Code, Die Index.

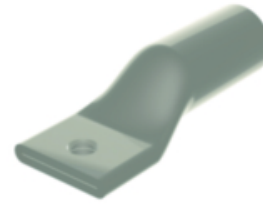

Application

Wire Termination

General

Catalog Number	YA8CA3
Color Code	Blue
Connector Type	DUAL RATED
Die Index	374
EU RoHS Indicator	Yes
Feature - Barrel Type	Standard
Finish Type	Tin-Plated
Material	ALUMINUM
Physical Attribute - Number of Holes	1
Physical Attribute - Tongue Type	Standard
Plated	Y
Plating Type	Tin - Electro Plated
Sub Brand	HYLUG
Temperature Rating	194
Trade Name	HYLUG™
Type	YA-A, Dual Rated
UPC	781810752401
UPC 12 Digit	7818107524011

Dimensions

Dimension - B Length fraction	5/8 in
Dimension - B Length inch	0.62 in
Dimension - Bolt Hole Size inch	0.27 in
Dimension - Bolt Size fraction	1/4
Dimension - Bolt Size inch	0.25
Dimension - D inch	0.75 in
Dimension - Hole Size fraction	1/4
Dimension - Hole Size inch	0.27
Dimension - Hole Size mm	6.9 mm
Dimension - L Length Overall mm	42 mm
Dimension - Length Overall inch	1.65 in
Dimension - N inch	0.25 in
Dimension - Outside Diameter inch	0.30 in
Dimension - Pad Width inch	0.53 in
Dimension - Strip Length inch	5/8

Electrical Ratings

Voltage - Maximum	35000
Voltage Rating	35 kV

Conductor Related

Conductor - AL Str Size	8 AWG
Conductor - AL Str Size Range	8 AWG
Conductor - Copper Str Size	8 AWG
Conductor - Copper Str Size Range	8 AWG
Conductor - Material	ALUMINUM / COPPER
Conductor Size	8 AWG
Conductor Type	CODE
Wire Size	8 AWG

Certifications And Compliance

Certification - CSA Approved	Yes
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	UL 486A-486B
Standards - Industry Standards Met	UL 486A-486B
Standards - RoHS Compliance Status	CM
UL Listed	Yes

Logistics

Carton Quantity	20
-----------------	----

Product Assets

[3D Models - YA8CA3_MODEL-PDF](#)
[3D Models - YA8CA3_MODEL-IGES](#)
[3D Models - YA8CA3_MODEL-STEP](#)
[Catalogs - Full Line BURNDY Catalog](#)
[Catalogs - Section C - Compression Connections](#)
[Customer Notices - Prop 65 Notice](#)
[Installation Manuals - Aluminum Installation Instructions](#)
[Sales Drawings - SD073935-01](#)

Dimension - Stud Size fraction 1/4
Dimension - Stud Size inch 1/4
Dimension - Z (inch) 0.50 in
Physical Attribute - Tongue Angle Straight



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.
BRDY_MX-YA8CA3-SPEC-EN | REV 6/2024