


YAV10T4, Uninsulated Ring Terminal For 12 - 10 AWG, 1-Hole, 3/8" Stud

By Burndy
Catalog # YAV10T4

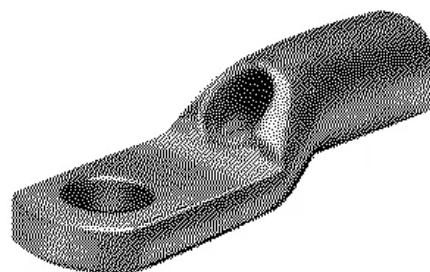

Copper Compression Lug, 1 Hole w/ Inspection Window, 14-10 AWG/12-10 AWG, 3/8" Stud, Short Barrel, Tin Plated.

Features

- Manufactured from seamless pure electrolytic copper tubing to provide maximum conductivity, low resistance and excellent ductility for crimping
- Seamless tubular crimp barrel design - No seams to split resulting in a very high quality electrical connection, also can be used on solid conductor
- Double thick tongue structurally a very strong terminal tongue
- Produced from tubular copper, extra copper material assures the compression connector will operate cooler than the conductors it connects
- Internally bevelled barrel for easy cable entry, especially for flexible conductors
- Inspection hole provides easy visual check for proper conductor insertion
- Electro-tin plated for a long lasting durable corrosion resistance

General

Application - For Use On	Copper Commercial (Code) Cable, Type AN Aircraft Cable, Extra Flexible Conductors
Catalog Number	YAV10T4
Connector Type	Ring Terminal
EU RoHS Indicator	Contact Manufacturer
Feature - Barrel Style	Chamfered
Feature - Barrel Type	Standard
Material	Copper
Military Specification	AS20659
Physical Attribute - Number of Holes	1
Physical Attribute - Tongue Type	Ring
Plated	Y
Plating Type	Tin - Electro Plated
Sub Brand	HYLUG
Trade Name	HYLUG™
Type	Ring Tongue
UPC	781810025284

Dimensions

Dimension - B Length fraction	3/8 in
Dimension - B Length inch	0.45 in
Dimension - Bolt Size fraction	3/8
Dimension - D inch	0.63 in
Dimension - Length Overall inch	1.17 in
Dimension - N inch	0.28 in
Dimension - Outside Diameter inch	0.21 in
Dimension - Pad Width inch	0.56 in
Dimension - Stud Size inch	3/8

Conductor Related

Conductor - Copper Solid Size Range	12 AWG;11 AWG;10 AWG
Conductor - Copper Solid Size Range	12 AWG-10 AWG
Conductor - Copper Str Size Range	12 AWG;10 AWG
Conductor - Copper Str Size Range	12 AWG-10 AWG
Conductor Size	12 - 10 AWG
Conductor Type	<ul style="list-style-type: none"> • CU C Solid-Size • CU C Str-Size

Certifications And Compliance

Certification - CSA Approved	Yes
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	<ul style="list-style-type: none"> • UL467 • Military Specified (Mil-Spec)
Standards - Industry Standards Met	<ul style="list-style-type: none"> • UL467 • Military Specified (Mil-Spec)
Standards - RoHS Compliance Status	CM
UL Listed	Yes

Logistics

Carton Quantity	500
Pallet Quantity	99999

Product Assets

[3D Models - YAV10T4_MODEL-STEP](#)
[3D Models - YAV10T4_MODEL-PDF](#)
[3D Models - YAV10T4_MODEL-IGES](#)
[Catalogs - BURNDY Master Catalog - Section B - Small Compression](#)
[Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)

[Installation Manuals - Copper Code Standard Terminals Tooling and Installation Instructions](#)
[Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
[Product Cross Section Image\(s\) - BUR_YAV18T5_LineArt](#)
[Sales Drawings - 50094160](#)
[Specifications - YAV10T4](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved
BRDY_MX-YAV10T4-SPEC-EN | REV 10/2024