


## YAV9CT9BOX, Uninsulated Ring Terminal For 10 - 9 AWG

By Burndy  
Catalog # [YAV9CT9BOX](#)

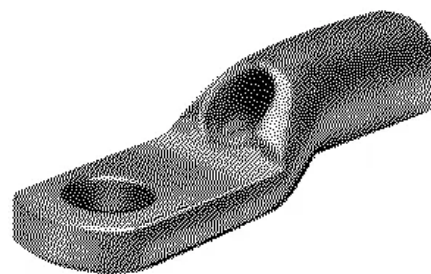

Seamless Uninsulated Compression Heavy Duty Ring Tongue Terminal.

### Features

- Manufactured from seamless pure electrolytic copper tubing to provide maximum conductivity, low resistance and excellent ductility for crimping
- Seamless tubular crimp barrel design - No seams to split resulting in a very high quality electrical connection, also can be used on solid conductor
- Double thick tongue structurally a very strong terminal tongue
- Produced from tubular copper, extra copper material assures the compression connector will operate cooler than the conductors it connects
- Internally bevelled barrel for easy cable entry, especially for flexible conductors
- Inspection hole provides easy visual check for proper conductor insertion
- Electro-tin plated for a long lasting durable corrosion resistance

### General

Catalog Number	YAV9CT9BOX
Connector Type	Ring Terminal
Feature - Barrel Style	Chamfered
Feature - Barrel Type	Standard
Material	Copper
Physical Attribute - Number of Holes	1
Physical Attribute - Tongue Type	Ring
Plated	Y
Plating Type	Tin - Electro Plated
Trade Name	HYLUG™
Type	Ring Tongue
UPC	781810532300
UPC 12 Digit	7818105323000

### Dimensions

Dimension - B Length fraction	2/5 in
Dimension - B Length inch	0.39 in
Dimension - Bolt Size fraction	1/4
Dimension - D inch	0.57 in
Dimension - Hole Size inch	0.27 in

Dimension - L Length Overall mm	29 mm
Dimension - Length Overall inch	1.15 in
Dimension - N inch	0.25 in
Dimension - Outside Diameter inch	0.23 in
Dimension - Pad Width inch	0.44 in
Dimension - Strip Length inch	7/16 in
Dimension - Z (inch)	0.31 in

### Conductor Related

Conductor - Copper Str Size	9 AWG
Conductor - Copper Str Size Range	9 AWG
Conductor Size	10 - 9 AWG
Conductor Type	<ul style="list-style-type: none"> <li>• CU C Solid-Size</li> <li>• CU C Str-Size</li> </ul>

### Certifications And Compliance

Certification - CSA Approved	Yes
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	UL467
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	CM
UL Listed	Yes

### Logistics

Carton Quantity	600
Pallet Quantity	99999

### Product Assets

[Catalogs - BURNDY Master Catalog - Section B - Small Compression](#)  
[Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)  
[Customer Notices - Prop 65 Notice](#)  
[Interactive Catalog - BURNDY Full-Line Digital Catalog](#)  
[Product Cross Section Image\(s\) - BUR\\_YAV10T3BOX\\_LineArt](#)  
[Sales Drawings - 50094160](#)



**A Hubbell brand**