


YC28C2, Copper C-Shape Connector

By Burndy
Catalog # [YC28C2](#)

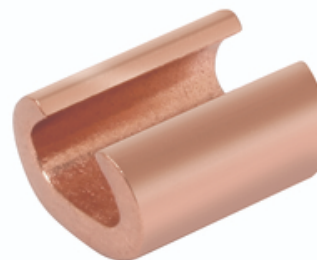

CU Compression C Shape Compression Connector, 600 Volts to 35 Kv, Run: 3/0 Str. - 4/0 Str., Tap: 6 Sol. - 2 Str.

Application

For Making Tap Or Parallel Copper Connections

General

Catalog Number	YC28C2
Die Index	F or D3
EU RoHS Indicator	Yes
Material	Copper
Plated	N
Plating Type	Unplated
Sub Brand	CRIMPIT
Trade Name	CRIMPIT™
Type	YC-C Series
UPC	781810115756
UPC 12 Digit	7818101157566

Dimensions

Dimension - Height inch	1.65 in
Dimension - L Length Overall mm	27 mm
Dimension - Length Overall inch	1.07 in

Conductor Related

Conductor - Copper Str Run Range	3/0 AWG-4/0 AWG
Conductor - Copper Str Tap Range	6 Sol. - 2 Str
Conductor Type	Cu C Sol-Size

Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	<ul style="list-style-type: none">UL 486AUL486B
Standards - Industry Standards Met	<ul style="list-style-type: none">UL 486AUL486B
Standards - RoHS Compliance	CM
Status	
UL Listed	Yes

Logistics

Carton Quantity	25
Pallet Quantity	5800

Product Assets

- [3D Models - YC28C2_MODEL-IGES](#)
- [3D Models - YC28C2_MODEL-STEP](#)
- [3D Models - YC28C2_MODEL-PDF](#)
- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Catalogs - BURNDY Master Catalog - Section H - Overhead Distribution](#)
- [Customer Notices - Prop 65 Notice](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Product Cross Section Image\(s\) - BUR_YCC_Lineart](#)
- [Sales Drawings - SE..090670-01](#)