


## YC4C8, Copper C-Shape Connector

By Burndy  
Catalog # [YC4C8](#)

CU Compression C Shape Compression Connector, 600 Volts to 35 Kv, Run: 6 Sol. - 4 Str., Tap: 8 Sol. - 8 Str.

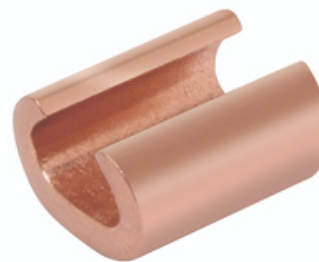

### Application

For Making Tap Or Parallel Copper Connections

### General

Catalog Number	YC4C8
Die Index	BG or 5/8
EU RoHS Indicator	Yes
Material	Copper
Plated	N
Plating Type	Unplated
Sub Brand	CRIMPIT
Trade Name	CRIMPIT™
Type	YC-C Series
UPC	781810114254
UPC 12 Digit	7818101142544

### Dimensions

Dimension - Height inch	0.73 in
Dimension - L Length Overall mm	16 mm
Dimension - Length Overall inch	0.62 in

### Conductor Related

Conductor - Copper Solid Run Range	6 Sol. - 4 Str.
Conductor - Copper Solid Tap	8 AWG
Conductor - Copper Str Run Range	6 Sol. - 4 Str.
Conductor - Copper Str Tap	8 AWG
Conductor Type	Cu C Sol-Size

### Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	<ul style="list-style-type: none"><li>UL 486A</li><li>UL486B</li></ul>
Standards - Industry Standards Met	<ul style="list-style-type: none"><li>UL 486A</li><li>UL486B</li></ul>
Standards - RoHS Compliance	CM
Status	
UL Listed	Yes

### Logistics

Carton Quantity	100
Pallet Quantity	57600

### Product Assets

- [3D Models - YC4C8\\_MODEL-STEP](#)
- [3D Models - YC4C8\\_MODEL-PDF](#)
- [3D Models - YC4C8\\_MODEL-IGES](#)
- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Catalogs - BURNDY Master Catalog - Section H - Overhead Distribution](#)
- [Customer Notices - Prop 65 Notice](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Product Cross Section Image\(s\) - BUR\\_YCC\\_Lineart](#)
- [Sales Drawings - SE..090670-01](#)