


YC8C8, Copper C-Shape Connector

By Burndy
Catalog # YC8C8

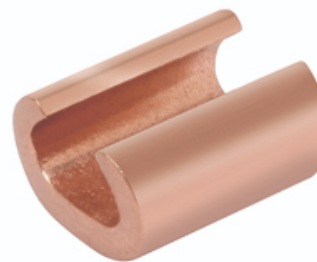

CU Compression C Shape Compression Connector, 600 Volts to 35 Kv, Run: 8 Sol. - 8 Str., Tap: 10 Sol. - 8 Str.

Application

For Making Tap Or Parallel Copper Connections

General

Catalog Number	YC8C8
Die Index	162
EU RoHS Indicator	Yes
Material	Copper
Plated	N
Plating Type	Unplated
Sub Brand	CRIMPIT
Trade Name	CRIMPIT™
Type	YC-C Series
UPC	781810114506
UPC 12 Digit	7818101145066

Dimensions

Dimension - Height inch	0.46 in
Dimension - L Length Overall mm	13 mm
Dimension - Length Overall inch	0.50 in

Conductor Related

Conductor - Copper Solid Run	8 AWG
Conductor - Copper Solid Tap	10 AWG;9 AWG;8 AWG
Conductor - Copper Solid Tap Range	10 Sol. - 8 Str.
Conductor - Copper Str Run	8 AWG
Conductor - Copper Str Tap Range	10 Sol. - 8 Str.
Conductor Type	Cu C Sol-Size

Certifications And Compliance

Certification - CSA Approved Industry Standard(s)	No
	<ul style="list-style-type: none"> UL 486A UL486B
Standards - Industry Standards Met	<ul style="list-style-type: none"> UL 486A UL486B
Standards - RoHS Compliance	CM
Status	
UL Listed	Yes

Logistics

Carton Quantity	100
-----------------	-----

Product Assets

- [3D Models - YC8C8_MODEL-STEP](#)
- [3D Models - YC8C8_MODEL-IGES](#)
- [3D Models - YC8C8_MODEL-PDF](#)
- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Catalogs - BURNDY Master Catalog - Section H - Overhead Distribution](#)
- [Customer Notices - Prop 65 Notice](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Product Cross Section Image\(s\) - BUR_YCC_Lineart](#)
- [Sales Drawings - SE..090670-01](#)
- [Specifications - YC8C8](#)