


# YGHHC29C29 Compression Grounding C-TAP Connector

By Burndy  
Catalog # [YGHHC29C29](#)

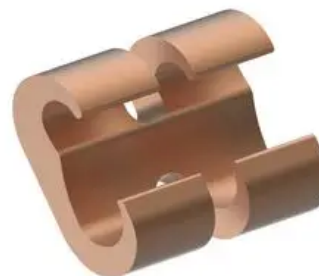

Compression ground connector, Material: Copper, Range Run: 3/0 Str-250 Kcmil, Tap: 3/0 Str-250 Kcmil.

## Application

For Direct Burial cables

## General

Catalog Number	YGHHC29C29
Connector Type	Tap
Die Index	997
EU RoHS Indicator	Contact Manufacturer
Material	Copper
Plated	N
Sub Brand	HYTAP
Trade Name	HYTAP™
Type	Taps
UPC	621945456242
UPC 12 Digit	6219454562422

## Dimensions

Dimension - Height mm	0 mm
-----------------------	------

## Conductor Related

Conductor - Copper Str Run Range	3/0 Stranded - 250 kcmil
Conductor - Copper Str Tap Range	3/0 Stranded - 250 kcmil
Conductor - Rod Run Range	1/2"; 5/8"

## Certifications And Compliance

Certification - CSA Approved	[Delete]
Certification - UL Listed Direct Burial	Yes
Industry Standard(s)	<ul style="list-style-type: none"> <li>• UL 467</li> <li>• IEEE 837</li> <li>• IEEE 837 2014 Qualified</li> <li>• UL 486A-486B</li> </ul>
Standards - Industry Standards Met	<ul style="list-style-type: none"> <li>• UL467</li> <li>• IEEE 837</li> <li>• IEEE 837 2014 Qualified</li> <li>• UL 486A-486B</li> </ul>
Standards - RoHS Compliance Status	CM

## Logistics

Carton Quantity	40
Pallet Quantity	3840

## Product Assets

- [Catalogs - BURNDY Master Catalog - Section E1 - Compression Grounding](#)
- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Customer Notices - Prop 65 Notice](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Sales Drawings - 50064429](#)
- [Specifications - YGHHC29C29](#)