


YP25U25, Figure 3-shaped Aluminum Connector with adjustable spacer

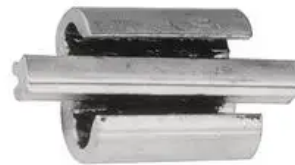

By Burndy
Catalog # [YP25U25](#)

Wide range, universal and reversible, Figure 3 shaped aluminum connector with adjustable overhanging spacer that separates conductors, Conductor Groove A Solid: 2/0, 3/0.

Features

- Wide range universal and reversible, Figure 3-shaped aluminum connector features adjustable overhanging spacer that separates conductors
- Spacer holds run or tap in place, permitting lineman to either approach the line ready to crimp or to assemble connector and tap on run and then crimp
- Massive aluminum design minimizes conductor corrosion due to galvanic action
- Pre-filled with PENETROX joint compound and stripsealed

Application

For Copper, Aluminum Or ACSR Conductors

General

Catalog Number	YP25U25
Die Index	D3
EU RoHS Indicator	Yes
Material	Aluminum
Plated	N
Plating Type	Unplated
Prefilled Oxide Inhibitor	Y
Sub Brand	CABELOK CRIMPIT
Trade Name	CABELOK™ CRIMPIT™
Type	YP-U
UPC	781810130322
UPC 12 Digit	7818101303222

Dimensions

Dimension - Height inch	1.70 in
Dimension - Height mm	0 mm
Dimension - Length Overall inch	1.69 in
Dimension - Width inch	0.97 in

Conductor Related

Conductor - ACSR Str Size A Range	1 (6/1) Robin AWG; 1/0 (6/1) Raven AWG
Conductor - ACSR Str Size B Range	1 (6/1) Robin AWG-1/0 (6/1) Raven AWG

Conductor - ACSR Str Size B Range	1 (6/1) Robin AWG; 1/0 (6/1) Raven AWG
Conductor - ACSR Str Size B Range	1 (6/1) Robin AWG-1/0 (6/1) Raven AWG
Conductor - AL Str Size A Range	1 AWG; 1/0 AWG
Conductor - AL Str Size A Range	1 AWG-1/0 AWG
Conductor - AL Str Size B Range	1 AWG; 1/0 AWG
Conductor - AL Str Size B Range	1 AWG-1/0 AWG
Conductor - Copper Solid Size A	2/0 AWG; 3/0 AWG
Conductor - Copper Solid Size A Range	2/0 AWG-3/0 AWG
Conductor - Copper Solid Size B	2/0 AWG; 3/0 AWG
Conductor - Copper Solid Size B Range	2/0 AWG-3/0 AWG
Conductor - Copper Str Size A Range	1 AWG; 1/0 ; 2/0 AWG
Conductor - Copper Str Size A Range	1 AWG-2/0 AWG
Conductor - Copper Str Size B Range	1 AWG; 1/0 ; 2/0 AWG
Conductor - Copper Str Size B Range	1 AWG-2/0 AWG

Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	No

Product Assets

- [3D Models - YP25U25_MODEL-PDF](#)
- [3D Models - YP25U25_MODEL-STEP](#)
- [3D Models - YP25U25_MODEL-IGES](#)
- [Catalogs - BURNDY Master Catalog - Section H - Overhead Distribution](#)
- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)



A Hubbell brand