


## YP26AU2, Figure 3-shaped Aluminum Connector with adjustable spacer

By Burndy

Catalog # [YP26AU2](#)

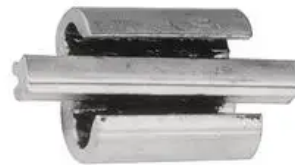

Wide range, universal and reversible, Figure 3 shaped aluminum connector with adjustable overhanging spacer that separates conductors, Conductor Groove A Solid: 1, 1/0, 2/0, 3/0.

### Features

- Wide range universal and reversible, Figure 3-shaped aluminum connector features adjustable overhanging spacer that separates conductors
- Spacer holds run or tap in place, permitting lineman to either approach the line ready to crimp or to assemble connector and tap on run and then crimp
- Massive aluminum design minimizes conductor corrosion due to galvanic action
- Pre-filled with PENETROX joint compound and stripealed

### Application

For Copper, Aluminum Or ACSR Conductors

### General

Catalog Number	YP26AU2
Die Index	O
EU RoHS Indicator	Yes
Material	Aluminum
Plated	N
Plating Type	Unplated
Prefilled Oxide Inhibitor	Y
Sub Brand	CABELOK CRIMPIT
Trade Name	CABELOK™ CRIMPIT™
Type	YP-U
UPC	781810130650
UPC 12 Digit	7818101306500

### Dimensions

Dimension - Height inch	1.30 in
Dimension - Length Overall inch	1.50 in
Dimension - Width inch	0.72 in

### Conductor Related

Conductor - ACSR Str Size A Range	3 (6/1) Swallow AWG; 2 (6/1) Sparrow AWG; 2 (7/1) Sparate AWG; 1 (6/1) Robin AWG; 1/0 (6/1) Raven AWG
-----------------------------------	---

Conductor - ACSR Str Size A Range	3 (6/1) Swallow AWG-1/0 (6/1) Raven AWG
Conductor - ACSR Str Size B Range	6 (6/1) Turkey AWG; 5 (6/1) Thrush AWG; 4 (6/1) Swan AWG; 4 (7/1) Swanate AWG; 3 (6/1) Swallow AWG; 2 (6/1) Sparrow AWG
Conductor - ACSR Str Size B Range	6 (6/1) Turkey AWG-2 (6/1) Sparrow AWG
Conductor - AL Str Size A Range	3 AWG; 2 AWG; 1 AWG; 1/0 AWG
Conductor - AL Str Size A Range	3 AWG-1/0 AWG
Conductor - AL Str Size B Range	6 AWG; 4 AWG; 3 AWG; 2 AWG
Conductor - AL Str Size B Range	6 AWG-2 AWG
Conductor - Copper Solid Size A Range	1 AWG; 1/0 AWG; 2/0 AWG; 3/0 AWG
Conductor - Copper Solid Size A Range	1 AWG-3/0 AWG
Conductor - Copper Solid Size B Range	6 AWG; 5 AWG; 4 AWG; 3 AWG; 2 AWG; 1 AWG; 1/0 AWG
Conductor - Copper Solid Size B Range	1 AWG-3/0 AWG
Conductor - Copper Str Size A Range	2 AWG; 1 AWG; 1/0 ; 2/0 AWG
Conductor - Copper Str Size A Range	2 AWG-2/0 AWG
Conductor - Copper Str Size B Range	6 AWG; 5 AWG; 4 AWG; 3 AWG; 2 AWG; 1 AWG
Conductor - Copper Str Size B Range	6 AWG-1 AWG

### Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	No

### Product Assets

3D Models - YP26AU2\_MODEL-IGES  
3D Models - YP26AU2\_MODEL-STEP  
3D Models - YP26AU2\_MODEL-PDF  
Catalogs - BURNDY Master Catalog - Section H - Overhead  
Distribution

Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog  
Interactive Catalog - BURNDY Full-Line Digital Catalog  
Product Cross Section Image(s) - BUR\_YPU\_Lineart  
Sales Drawings - sd045569-01  
Specifications - YP26AU2



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved  
BRDY\_MX-YP26AU2-SPEC-EN | REV 10/2024