


YP27AU2, Figure 3-shaped Aluminum Connector with adjustable spacer

By Burndy
Catalog # [YP27AU2](#)

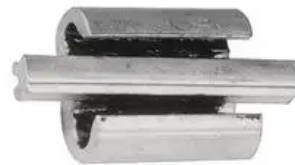

Wide range, universal and reversible, Figure 3 shaped aluminum connector with adjustable overhanging spacer that separates conductors, Conductor Groove A Solid: 2/0, 3/0, 4/0.

Features

- Wide range universal and reversible, Figure 3-shaped aluminum connector features adjustable overhanging spacer that separates conductors
- Spacer holds run or tap in place, permitting lineman to either approach the line ready to crimp or to assemble connector and tap on run and then crimp
- Massive aluminum design minimizes conductor corrosion due to galvanic action
- Pre-filled with PENETROX joint compound and stripealed

Application

For Copper, Aluminum Or ACSR Conductors

General

Catalog Number	YP27AU2
Die Index	D3
EU RoHS Indicator	Yes
Material	Aluminum
Plated	N
Plating Type	Unplated
Prefilled Oxide Inhibitor	Y
Sub Brand	CABELOK CRIMPIT
Trade Name	CABELOK™ CRIMPIT™
Type	YP-U
UPC	781810133989
UPC 12 Digit	7818101339899

Dimensions

Dimension - Height inch	1.70 in
Dimension - Length Overall inch	1.69 in
Dimension - Width inch	0.97 in

Conductor Related

Conductor - ACSR Str Size A Range	1/0 (6/1) Raven AWG; 2/0 (6/1) Quail AWG
Conductor - ACSR Str Size A Range	1/0 (6/1) Raven AWG-2/0 (6/1) Quail AWG

Conductor - ACSR Str Size B Range	4 (6/1) Swan AWG; 4 (7/1) Swanate AWG; 3 (6/1) Swallow AWG; 2 (6/1) Sparrow AWG; 2 (7/1) Sparate AWG
Conductor - ACSR Str Size B Range	4 (6/1) Swan AWG-2 (7/1) Sparate AWG
Conductor - AL Str Size A Range	1/0 AWG; 2/0 AWG
Conductor - AL Str Size A Range	1/0 AWG-2/0 AWG
Conductor - AL Str Size B Range	4 AWG; 3 AWG; 2 AWG
Conductor - AL Str Size B Range	4 AWG-2 AWG
Conductor - Copper Solid Size A Range	2/0 AWG; 3/0 AWG; 4/0 AWG
Conductor - Copper Solid Size A Range	2/0 AWG-4/0 AWG
Conductor - Copper Solid Size B Range	2 AWG; 1 AWG; 1/0 AWG
Conductor - Copper Solid Size B Range	2/0 AWG-4/0 AWG
Conductor - Copper Str Size A Range	1/0 ; 2/0 AWG; 3/0 AWG
Conductor - Copper Str Size A Range	1/0 -3/0 AWG
Conductor - Copper Str Size B Range	3 AWG; 2 AWG; 1 AWG
Conductor - Copper Str Size B Range	3 AWG-1 AWG

Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	No

Product Assets

- [3D Models - YP27AU2_MODEL-PDF](#)
- [3D Models - YP27AU2_MODEL-STEP](#)
- [3D Models - YP27AU2_MODEL-IGES](#)

Catalogs - BURNDY Master Catalog - Section H - Overhead
Distribution
Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog
Interactive Catalog - BURNDY Full-Line Digital Catalog

Product Cross Section Image(s) - BUR_YPU_Lineart
Sales Drawings - sd045569-01
Specifications - YP27AU2



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved
BRDY_MX-YP27AU2-SPEC-EN | REV 10/2024