


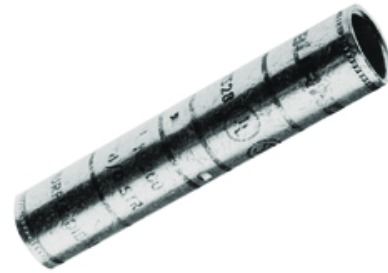

# YS1C, Cu Compression Splice, Long Barrel, 1 AWG

By Burndy  
Catalog # [YS1C](#)

1 AWG CU, Long Barrel, Internal Chamfer, Tin Plated, UL/CSA, 90°C, Up to 35kV, GREEN Color Code, 11 or 375 Die Index



## Application

Wire Splice

## General

Catalog Number	YS1C
Color Code	Green
Connector Type	LONG BARREL
Die Index	11
EU RoHS Indicator	Yes
Feature - Barrel Style	Chamfered
Feature - Barrel Type	Long
Finish Type	Tin-Plated
Material	COPPER
Plated	Y
Plating Type	Tin - Electro Plated
Sub Brand	HYLINK
Trade Name	HYLINK™
Type	YS, Long Barrel
UPC	781810506905
UPC 12 Digit	7818105069055

## Dimensions

Dimension - B Length inch	1.34 in
Dimension - L Length Overall mm	78 mm
Dimension - Length Overall inch	3.07 in
Dimension - Strip Length inch	1-7/16

## Electrical Ratings

Voltage - Maximum	35000
Voltage Rating	35 kV

## Conductor Related

Conductor - Copper Str Navy Size	75 (37) Navy
Conductor - Copper Str Size	1 AWG
Conductor - Material	COPPER
Conductor Size	1 AWG
Conductor Type	CODE
Wire Size	1 AWG

## Certifications And Compliance

Certification - CSA Approved	Yes
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	UL 486A-486B
Standards - Industry Standards Met	UL 486A-486B
Standards - RoHS Compliance Status	CM
UL Listed	Yes

## Logistics

Carton Quantity	20
-----------------	----

## Product Assets

[3D Models - YS1C\\_MODEL-PDF](#)  
[3D Models - YS1C\\_MODEL-IGES](#)  
[3D Models - YS1C\\_MODEL-STEP](#)  
[Catalogs - Full Line BURNDY Catalog](#)  
[Catalogs - Section C - Compression Connections](#)  
[Customer Notices - Prop 65 Notice](#)  
[Sales Drawings - SD007774-01](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.  
BRDY\_MX-YS1C-SPEC-EN | REV 6/2024