




# YS36, Cu Compression Splice, Long Barrel, 600 kcmil

By Burndy  
Catalog # [YS36](#)

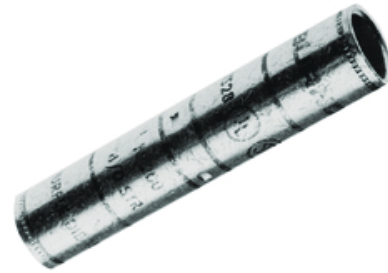

600 kcmil CU, Long Barrel, Internal Chamfer, Tin Plated,  
UL/CSA, 90°C, Up to 35kV, GREEN Color Code, 22 or 472 Die  
Index.

## Application

Wire Splice

## General

Catalog Number	YS36
Color Code	Green
Connector Type	LONG BARREL
Die Index	22
EU RoHS Indicator	Yes
Feature - Barrel Style	Chamfered
Feature - Barrel Type	Long
Finish Type	Tin-Plated
Material	COPPER
Plated	Y
Plating Type	Tin - Electro Plated
Sub Brand	HYLINK
Trade Name	HYLINK™
Type	YS, Long Barrel
UPC	781810526255
UPC 12 Digit	7818105262555

## Dimensions

Dimension - B Length inch	2.63 in
Dimension - L Length Overall mm	149 mm
Dimension - Length Overall inch	5.85 in
Dimension - Strip Length inch	2-11/16

## Electrical Ratings

Voltage - Maximum	35000
Voltage Rating	35 kV

## Conductor Related

Conductor - Copper Str Size	600 kcmil
Conductor - Material	COPPER
Conductor Size	600 KCMIL
Conductor Type	CODE
Wire Size	600 kcmil

## Certifications And Compliance

Certification - CSA Approved	Yes
Industry Standard(s)	UL 486A-486B
Standards - Industry Standards Met	UL 486A-486B
Standards - RoHS Compliance Status	CM
UL Listed	Yes

## Logistics

Carton Quantity	6
-----------------	---

## Product Assets

[3D Models - YS36\\_MODEL-PDF](#)  
[3D Models - YS36\\_MODEL-STEP](#)  
[3D Models - YS36\\_MODEL-IGES](#)  
[Catalogs - Full Line BURNDY Catalog](#)  
[Catalogs - Section C - Compression Connections](#)  
[Customer Notices - Prop 65 Notice](#)  
[Sales Drawings - SD007774-01](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.  
BRDY\_MX-YS36-SPEC-EN | REV 6/2024