




Straight Blade Devices, Receptacles, Quad-PLEX, Commercial/Industrial Grade, 15A 125V, 2-Pole 3-Wire Grounding, 5- 15R, Gray, Single Pack

By Bryant
Catalog # 1254GY

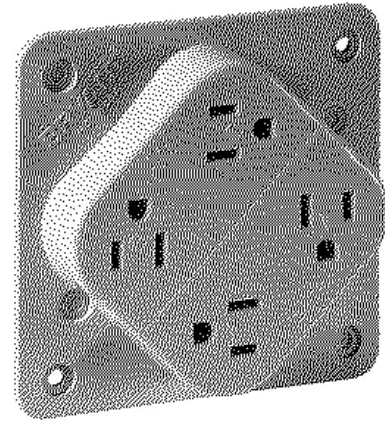

Straight Blade Devices, Receptacles, Quad-PLEX,
Commercial/Industrial Grade, 15A 125V, 2-Pole 3-Wire
Grounding, 5-15R, Gray, Single Pack

Features

- Quad-PLEX
- Commercial/Industrial Grade
- 15A 125V
- 2-Pole 3-Wire Grounding
- 5-15R

Application

Commercial/Industrial

General

Catalog Number	1254GY
Color	Gray
EU RoHS Indicator	Yes
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Item Type	Smooth Face
Material	Composite
Material - Mounting Hardware	Screw Mounting
Number Of Outlets	4
Number Of Poles	2-Pole
OEM Brand Name	Hubbell Bryant
Series	Commercial
Type	Four Outlet Receptacle
UPC	781786336292

Dimensions

Dimensions	4.3 in x 4.30 in x 0.92 in
Display Size	Standard Sized Product
Height	0.92 in

Length	4.3 in
Weight	0.35 lb
Width	4.3 in

Electrical Ratings

Amperage Rating	15 A
Connectivity	Terminals
Current / Amperage Rating	15 A
Current Rating	15 A
Phase	Single Phase
Voltage Rating	125 V
Voltage Rating Description	125 V
Wattage	1875

Conductor Related

Number Of Wires	3-Wire
Wire Size	#14 AWG to #12 AWG

Certifications And Compliance

Nema Rating	5-15R
Standards - RoHS Compliance Status	CM

Logistics

Carton Quantity	10
-----------------	----

Product Assets

[Catalog Page - BRY A-15 Catalog Page](#)
[Catalogs - Bryant Full Line Catalog](#)
[Specifications - 1254GY](#)