


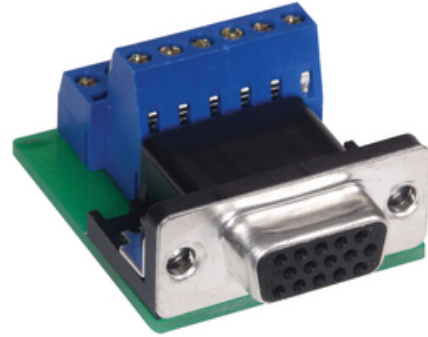

## Audio/Video Connector, D-Sub, 15-Pin VGA, ScrewTerminal, 10 Pack

By Bryant  
Catalog # [15ST10](#)

Audio/Video Connector, D-Sub, 15-Pin VGA, ScrewTerminal, 10 Pack



### General

Contact	Beryllium Copper
EU RoHS Indicator	Yes
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Item Type	iSTATION VGA Analog Video Connections
Material - Mounting Hardware	Snap-On- Snap-Fit
Style	HD, 15-Pin
Temperature Rating	Per TIA
Type	Screw Term
UPC	662620843735

### Dimensions

Display Size	Standard Sized Product
--------------	------------------------

### Electrical Ratings

Connectivity	Screw Terminals
Contact Resistance	100 Ohm
Withstand Voltage	1000V RMS, 1414V DC

### Logistics

Carton Quantity	25
-----------------	----

### Product Assets

[Catalog Page - Bryant R-17 Catalog page](#)  
[Catalogs - Bryant Full Line Catalog](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.  
BRY-15ST10-SPEC-EN | REV 5/2023