


Heavy Duty Products, IEC Pin and Sleeve Devices, Industrial Grade, Female Connector Body, 30A 3-Phase Delta 600V AC, Watertight

By Bryant
Catalog # 430C5W

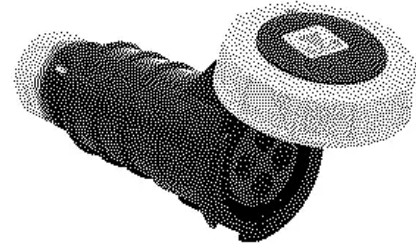

Heavy Duty Products, IEC Pin and Sleeve Devices, Industrial Grade, Female Connector Body, 30A 3-Phase Delta 600V AC, 3-Pole 4-Wire Grounding, Screw Terminals, Black, Watertight

Features

- Industrial Grade
- Female Connector Body
- 30A 3-Phase Delta 600V AC
- 3- Pole 4-Wire Grounding
- Screw Terminals

Application

High Ampacity Connections

General

| | |
|------------------------------|---|
| Catalog Number | 430C5W |
| Color | Black |
| EU RoHS Indicator | Yes |
| Environmental Conditions | Watertight |
| Insulation | Insulated Body |
| Item Type | Watertight |
| Material | Composite |
| Material - Mounting Hardware | Cord Mounted |
| Number Of Poles | 3-Pole |
| OEM Brand Name | Hubbell Bryant |
| Series | Watertight - IP67 |
| Temperature Rating | Maximum Continuous: 75° C; Minimum Continuous: -40° C w/o impact, -25° with impact. |

| | |
|------|--------------|
| Type | Connector |
| UPC | 781786251182 |

Dimensions

| | |
|--------------|------------------------|
| Display Size | Standard Sized Product |
|--------------|------------------------|

Electrical Ratings

| | |
|----------------------------|--------------------------|
| Amperage Rating | 30 A |
| Connectivity | Pressure Terminal Screws |
| Current / Amperage Rating | 30 A |
| Current Rating | 30 A |
| Voltage Rating | 3 Phase 600 V |
| Voltage Rating Description | 3 Phase 600V |

Conductor Related

| | |
|----------------------|-------------------|
| Conductor Range | #12 AWG to #8 AWG |
| Number Of Wires | 4-Wire |
| Number of Conductors | 4-Wire Grounding |

Certifications And Compliance

| | |
|-------------|----------|
| Nema Rating | Non-NEMA |
|-------------|----------|

Product Assets

[Specifications - 430C5W](#)