




# Locking Devices, Locking Devices, Industrial, Duplex Receptacle, 15A 125V, 2-Pole 3-Wire Grounding, L5-15R, Screw Terminal, Brown

By Bryant  
Catalog # 4700DR

Locking Devices, Industrial, Duplex Receptacle, 15A 125V, 2-Pole 3-Wire Grounding, L5-15R, Screw Terminal, Brown

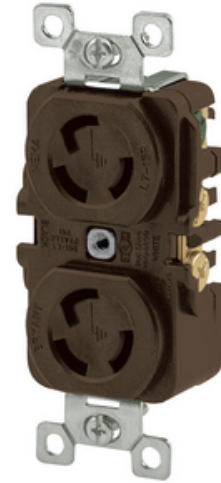

## Features

- Reinforced thermoplastic construction
- Single piece, all brass contacts
- Single point break-off tabs
- Mounting strap tabs lock the body and base together

## Application

Extra Heavy Duty Industrial Specification Grade

## General

Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Item Type	15A Duplex Receptacle
Material	Composite
Material - Mounting Hardware	Screw Mounting
Number Of Poles	2-Pole
OEM Brand Name	Hubbell Bryant
Style	Duplex Receptacle
Type	Receptacle
UPC	781786002005

## Dimensions

Dimensions	3.28 in x 1.70 in x 0.93 in
Display Size	Standard Sized Product
Height	0.93 in
Length	3.28 in
Width	1.70 in

## Electrical Ratings

Amperage Rating	15 A
Connectivity	Terminal Screws
Current Rating	15 A
Phase	Single Phase
Voltage Rating	125 V
Voltage Rating Description	125V

## Conductor Related

Number Of Wires	3-Wire
Wire Size	#14 AWG to #8 AWG

## Certifications and Compliance

Nema Rating	L5-15R
-------------	--------

## Logistics

Carton Quantity	10
-----------------	----

## Product Assets

[Catalog Page - Bryant H-7 Catalog page](#)  
[Catalogs - Bryant Full Line Catalog](#)  
[Literature - General Literature - BRYANT® Wiring Devices](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.  
BRY-4700DR-SPEC-EN | REV 5/2023