




Straight Blade Devices, Locking Devices, Industrial, Combination Face Duplex Receptacle, 15A 125V, 2-Pole 3-Wire Grounding, L5-15R, Screw Terminal

By Bryant
Catalog # [4792DR](#)

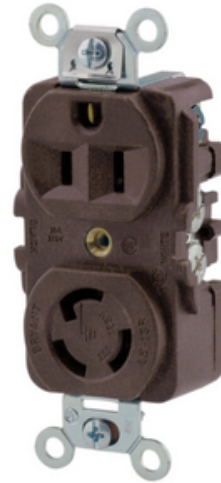

Straight Blade Devices, Locking Devices, Industrial, Combination Face Duplex Receptacle, 15A 125V, 2-Pole 3-Wire Grounding, L5-15R, Screw Terminal, Reinforced thermoplastic polyester, 1 feed, 1 return, Brown

Application

Extra Heavy Duty Industrial Specification Grade

General

| | |
|------------------------------|---|
| Color | Brown |
| Environmental Conditions | Indoor Dry Unless Protected By Additional Means |
| Item Type | Traditional Duplex |
| Material - Mounting Hardware | Screw Mounting |
| Number Of Poles | 2-Pole |
| OEM Brand Name | Hubbell Bryant |
| Series | Heavy Duty |
| Style | Finder Groove Face |
| Type | Combination Receptacle |
| UPC | 781786657069 |

Dimensions

| | |
|--------------|-----------------------------|
| Dimensions | 4.06 in x 1.69 in x 1.19 in |
| Display Size | Standard Sized Product |
| Height | 1.19 in |
| Length | 4.06 in |
| Weight | 0.3 lb |
| Width | 1.69 in |

Electrical Ratings

| | |
|----------------------------|---------------------|
| Amperage Rating | 15 A |
| Connectivity | Back and Side Wired |
| Current / Amperage Rating | 15 A |
| Current Rating | 15 A |
| Phase | Single Phase |
| Voltage Rating | 125 V |
| Voltage Rating Description | 125 V |
| Wattage | 3750 |

Conductor Related

| | |
|-----------------|--------------------|
| Number Of Wires | 3-Wire |
| Wire Size | #14 AWG to #12 AWG |

Certifications and Compliance

| | |
|-------------|---------------|
| Nema Rating | 5-15R, L5-15R |
|-------------|---------------|

Logistics

| | |
|-----------------|----|
| Carton Quantity | 10 |
|-----------------|----|

Product Assets

[Catalog Page - Bryant A-11 Catalog page](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
BRY-4792DR-SPEC-EN | REV 5/2023