




Straight Blade Devices, Short Yoke Receptacles, Panel Mount Single, Commercial/Industrial Grade, Side Wired, Urea Face, 15A 125V, 5-15R

By Bryant
Catalog # 5258

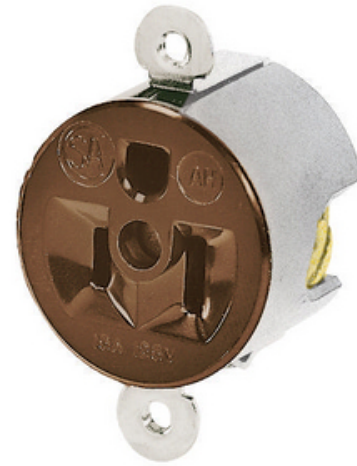

Straight Blade Devices, Short Yoke Receptacles, Panel Mount Single, Commercial/Industrial Grade, 2-Pole 3-Wire Grounding, Side Wired, Urea Face, 15A 125V, 5-15R, Brown, Single Pack

Application

Extra Heavy Duty Industrial Specification Grade

General

Color	Brown
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Item Type	Panel Mount Single
Material - Mounting Hardware	Screw Mounting
Number Of Poles	2-Pole
OEM Brand Name	Hubbell Bryant
Series	Extra Heavy Duty
Style	Finder Groove Face
Type	Single Receptacle
UPC	781786659209

Dimensions

Dimensions	2.25 in x 1.38 in x 0.85 in
Display Size	Standard Sized Product
Height	0.85 in
Length	2.25 in
Weight	0.15 lb
Width	1.38 in

Electrical Ratings

Amperage Rating	20 A
Connectivity	Side Wired Only
Current / Amperage Rating	15 A
Current Rating	20 A
Phase	Single Phase
Voltage Rating	125 V
Voltage Rating Description	125 V
Wattage	1875

Conductor Related

Number Of Wires	3-Wire
Wire Size	#14 AWG to #12 AWG

Certifications and Compliance

Nema Rating	5-15R
-------------	-------

Logistics

Carton Quantity	10
-----------------	----

Product Assets

[Catalog Page - Bryant Q-18 Catalog page](#)
[Catalog Page - Bryant A-9 Catalog page](#)
[Catalogs - Bryant Full Line Catalog](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
BRY-5258-SPEC-EN | REV 5/2023