




Straight Blade Devices, Receptacles, Flush Mount, Single, Commercial/Industrial Grade, Reinforced Thermoplastic Polyester, 30A 125/250V

By Bryant
Catalog # 9303

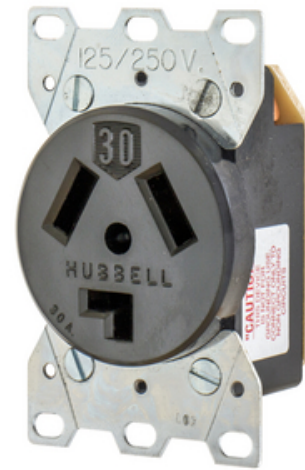

Straight Blade Devices, Receptacles, Flush Mount, Single,
Commercial/Industrial Grade, Reinforced Thermoplastic
Polyester, 30A 125/250V, 3-Pole 3-Wire Non-Grounding, 10-
30R, Black, Single Pack.

General

Color	Black
Number Of Poles	3-Pole
OEM Brand Name	Hubbell Bryant
Series	Heavy Duty
Style	Smooth Face
Type	Single Receptacle
UPC	781786632233

Dimensions

Weight	0.35 lb
--------	---------

Electrical Ratings

Amperage Rating	30 A
Current / Amperage Rating	30 A
Current Rating	30 A
Voltage Rating	125/250 VAC
Voltage Rating Description	125/250 VAC

Conductor Related

Number Of Wires	3 Wire
-----------------	--------

Certifications and Compliance

Nema Rating	10-30R
-------------	--------

Logistics

Carton Quantity	25
-----------------	----

Product Assets

[Catalog Page - Bryant A-26 Catalog page](#)
[Catalog Page - Bryant Q-18 Catalog page](#)
[Catalogs - Bryant Full Line Catalog](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
BRY-9303-SPEC-EN | REV 7/2023