




Straight Blade Devices, Receptacles, Flush Mount, Single, Commercial/Industrial Grade, Reinforced Thermoplastic Polyester, 50A 125/250V

By Bryant
Catalog # 9306

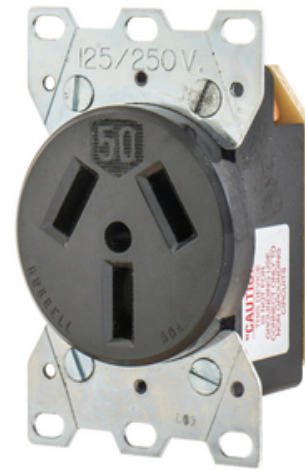

Straight Blade Devices, Receptacles, Flush Mount, Single, Commercial/Industrial Grade, Reinforced Thermoplastic Polyester, 50A 125/250V, 3-Pole 3-Wire Non-Grounding, 10-50R, Black, Single Pack.

Application

Industrial Grade

General

Color	Black
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Item Type	Single
Material - Mounting Hardware	Screw Mounting
Number Of Poles	3-Pole
OEM Brand Name	Hubbell Bryant
Series	Heavy Duty
Type	Single Receptacle
UPC	781786632264

Dimensions

Display Size	Standard Sized Product
Weight	0.4 lb

Electrical Ratings

Amperage Rating	50 A
Connectivity	Pressure Terminal Screws
Current / Amperage Rating	50 A
Current Rating	50 A
Phase	Single Phase
Voltage Rating	125/250 V
Voltage Rating Description	125/250 V
Wattage	12500

Conductor Related

Number Of Wires	3-Wire
Wire Size	#10 AWG to #6 AWG

Certifications and Compliance

Nema Rating	10-50P
-------------	--------

Logistics

Carton Quantity	25
-----------------	----

Product Assets

[Catalog Page - Bryant A-27 Catalog page](#)
[Catalog Page - Bryant Q-18 Catalog page](#)
[Catalogs - Bryant Full Line Catalog](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
BRY-9306-SPEC-EN | REV 7/2023