




# Straight Blade Devices, Receptacles, Flush Mount Single, Commercial/Industrial Grade, Reinforced Thermoplastic Polyester, 50A 125V

By Bryant  
Catalog # [9530IG](#)

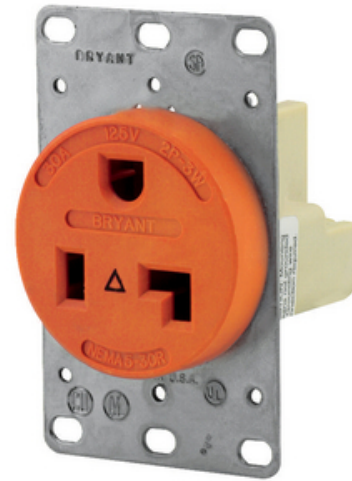

Straight Blade Devices, Receptacles, Flush Mount Single,  
Commercial/Industrial Grade, Reinforced Thermoplastic  
Polyester, 50A 125V, 2-Pole 3-Wire Grounding, 5-50R, Orange,  
Single Pack, Isolated Ground

## Application

Industrial Grade

## General

Color	Orange
EU RoHS Indicator	Yes
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Item Type	Single
Material	Composite
Material - Mounting Hardware	Screw Mounting
Number Of Poles	2-Pole
OEM Brand Name	Hubbell Bryant
Series	Straight Blade
Style	Extra Heavy Duty
Type	Single Receptacle
UPC	781786731066

## Dimensions

Display Size	Standard Sized Product
Weight	0.4 lb

## Electrical Ratings

Amperage Rating	30 A
Connectivity	Pressure Terminal Screws
Current / Amperage Rating	30 A
Current Rating	30 A
Phase	Single Phase
Voltage Rating	125 V
Voltage Rating Description	125 V
Wattage	3750

## Conductor Related

Number Of Wires	3-Wire
Wire Size	#10 AWG to #6 AWG

## Certifications and Compliance

Nema Rating	5-30R
-------------	-------

## Logistics

Carton Quantity	5
-----------------	---

## Product Assets

[Catalog Page - Bryant A-26 Catalog page](#)  
[Catalogs - Bryant Full Line Catalog](#)  
[Literature - General Literature - Heavy Duty Straight Blade](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.  
BRY-9530IG-SPEC-EN | REV 7/2023