




Straight Blade Devices, Receptacles, Flush Mount Single, Commercial/Industrial Grade, Reinforced Thermoplastic Polyester, 30A 250V, 6-30R

By Bryant
Catalog # 9630FR

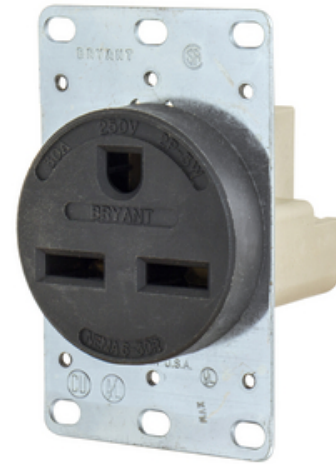

Straight Blade Devices, Receptacles, Flush Mount
Single, Commercial/Industrial Grade, Reinforced Thermoplastic
Polyester, 30A 250V, 2-Pole 3-Wire Grounding, 6-30R, Black,
Single Pack

Application

Industrial Grade

General

Color	<ul style="list-style-type: none">• Black• Noir
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Item Type	Single
Material - Mounting Hardware	Screw Mounting
Number Of Poles	2-Pole
OEM Brand Name	Hubbell Bryant
Series	Heavy Duty
Style	Smooth Face
Type	Single Receptacle
UPC	781786677289

Dimensions

Display Size	Standard Sized Product
Weight	0.45 lb

Electrical Ratings

Amperage Rating	30 A
Connectivity	Pressure Terminal Screws
Current / Amperage Rating	30 A
Current Rating	30 A
Phase	Single Phase
Voltage Rating	250 V
Voltage Rating Description	250 V
Wattage	7500

Conductor Related

Number Of Wires	3-Wire
Wire Size	#10 AWG to #6 AWG

Certifications and Compliance

Nema Rating	6-30R
-------------	-------

Logistics

Carton Quantity	25
-----------------	----

Product Assets

[Catalog Page - Bryant A-26 Catalog page](#)
[Catalog Page - Bryant Q-18 Catalog page](#)
[Catalogs - Bryant Full Line Catalog](#)
[Literature - General Literature - Heavy Duty Straight Blade](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
BRY-9630FR-SPEC-EN | REV 7/2023