




# IEC Pin and Sleeve, Watertight Plug, 60 A, 3 Phase 480 VAC

By Bryant  
Catalog # [BRY460P7W](#)

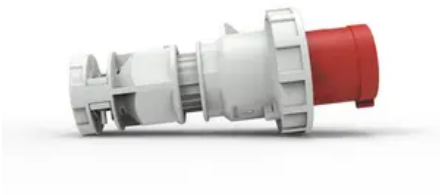

Heavy Duty Products, IEC Pin and Sleeve Devices, Male, Plug, 60 A 3 Phase 480 VAC, 3-POLE 4-WIRE, Red, Watertight

### Features

- IP67 environmental ratings
- Impact and corrosion resistant insulated non-metallic housing
- Sequential contact engagement to prevent a momentary over-voltage
- External strain relief
- Glandless water ingress protection

### Application

High Ampacity Connections

### General

Catalog Number	BRY460P7W
Color	Red
Environmental Conditions	IP67
Ingress Protection	IP67
Insulation	Insulated Body
Material	PBT
Mounting Type	Cord Mounted
Number Of Poles	3-POLE
Series	Watertight IP67
Size	Standard
Temperature Rating	Maximum Continuous: 75° C; Minimum Continuous: -40° C w/o impact, -25° with impact.
Type	Plug
UPC	781786782327

### Electrical Ratings

Amperage Rating	60 A
Current / Amperage Rating	60 A
Dielectric Strength	Withstand 3000V AC
Voltage - Maximum	600 VAC
Voltage Rating	3 Phase 480 VAC
Voltage Rating Description	3 Phase 480 VAC

### Conductor Related

Number Of Wires	4-WIRE
Wire Size	#6 AWG to #4 AWG

### Certifications And Compliance

Industry Standard(s)	All constructions are UL Listed & cUL Listed, FileE14633, UL1686 Standard for Pin & Sleeve Configurations, CE
Nema Rating	Non-NEMA

### Logistics

Carton Quantity	5
Pallet Quantity	150

### Product Assets

- [Catalog Page - BRY K-11 Catalog Page](#)
- [Catalog Page - BRY K-4 Catalog Page](#)
- [Catalogs - Bryant Full Line Catalog](#)
- [Sales Drawings - M14030](#)
- [Specifications - BRYANT\\_BRY460P7W\\_spec](#)



A Hubbell brand