




Straight Blade Devices, Female Connector Body, Corrosion Resistant, Industrial/Commercial Grade, Straight, 15A 125V, 2- Pole 3-Wire Grounding, 5-15R

By Bryant
Catalog # [BRY5269NCCR](#)

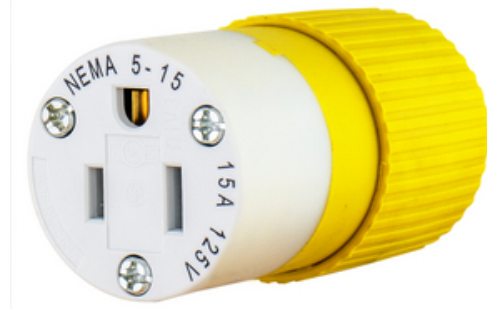

Straight Blade Devices, Female Connector Body, Corrosion Resistant, Industrial/Commercial Grade, Straight, 15A 125V, 2-Pole 3-Wire Grounding, 5-15R, Yellow, Single Pack

Application

Extra Heavy Duty Industrial Grade

General

Color	Yellow
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Insulation	Insulated Body
Item Type	Tech-Spec Triple Gripper
Material	Composite
Material - Mounting Hardware	Cord Mounted
Number Of Poles	2-Pole
OEM Brand Name	Hubbell Bryant
Series	Industrial
Style	Extra Heavy Duty
Temperature Rating	Maximum Continuous: 75° C; Minimum Continuous: -40° C w/o impact, -25° with impact.
Type	Connector Body
UPC	781786134096

Dimensions

Dimensions	2.95 in x 1.52 in x 1.38 in
Display Size	Standard Sized Product
Height	1.38 in
Length	2.95 in
Weight	0.1 lb
Width	1.52 in

Electrical Ratings

Amperage Rating	15 A
Connectivity	Screw Terminals
Current / Amperage Rating	15 A
Current Rating	15 A
Voltage Rating	125 V
Voltage Rating Description	125 V

Conductor Related

Conductor Range	#14 AWG to #10 AWG
Number Of Conductors	3-Wire Grounding
Number Of Wires	3-Wire

Certifications and Compliance

Nema Rating	5-15R
-------------	-------

Logistics

Carton Quantity	10
-----------------	----

Product Assets

[Catalog Page - Bryant J-2 Catalog page](#)
[Catalog Page - Bryant A-20 Catalog page](#)
[Catalogs - Bryant Full Line Catalog](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
BRY-BRY5269NCCR-SPEC-EN | REV 7/2023