




Straight Blade Devices, Receptacles, Duplex, Commercial/Industrial Grade, Corrosion Resistant, 20A 250V, 2- Pole 3-Wire Grounding, 6-20R, Single Pack

By Bryant
Catalog # [BRY5462CR](#)

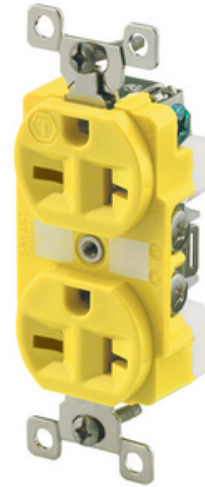

Straight Blade Devices, Receptacles, Duplex,
Commercial/Industrial Grade, Corrosion Resistant, 20A 250V,
2-Pole 3-Wire Grounding, 6-20R, Yellow, Single Pack

Application

Extra Heavy Duty Industrial Specification Grade

General

Color	Yellow
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Item Type	Traditional Duplex
Material - Mounting Hardware	Screw Mounting
Number Of Poles	2-Pole
OEM Brand Name	Hubbell Bryant
Series	Extra Heavy Duty
Style	Finder Groove Face
Type	Duplex Receptacle
UPC	781786005419

Dimensions

Dimensions	3.28 in x 1.54 in x 1.16 in
Display Size	Standard Sized Product
Height	1.16 in
Length	3.28 in
Weight	0.2 lb
Width	1.54 in

Electrical Ratings

Amperage Rating	20 A
Connectivity	Back and Side Wired
Current / Amperage Rating	20 A
Current Rating	20 A
Phase	Single Phase
Voltage Rating	250 V
Voltage Rating Description	250 V
Wattage	5000

Conductor Related

Number Of Wires	3-Wire
Wire Size	#14 AWG to #12 AWG

Certifications and Compliance

Nema Rating	6-20R
-------------	-------

Logistics

Carton Quantity	10
-----------------	----

Product Assets

[Catalog Page - Bryant J-2 Catalog page](#)
[Catalog Page - Bryant A-8 Catalog page](#)
[Catalogs - Bryant Full Line Catalog](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
BRY-BRY5462CR-SPEC-EN | REV 7/2023