




Locking Devices, Watertight Series, Receptacle, Duplex, 15A 250V, 2-Pole 3-Wire Grounding, L6-15R, Yellow

By Bryant
Catalog # [BRY65W49D](#)

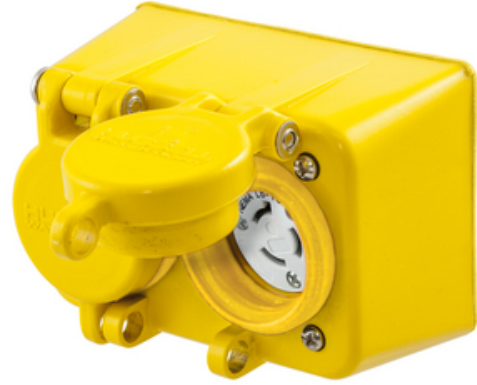

Watertight Series, Locking Receptacle, Duplex, 15A 250V, 2-Pole 3-Wire Grounding, L6-15R, Yellow

Features

- Impact-resistant PBT material lid and cover plate
- Stainless steel mounting hardware
- Lockable cover meets OSHA Lockout/Tagout regulations
- Thermoplasticelastomer seal

General

Color	Yellow
Item Type	15A Watertight Duplex Receptacle
Number Of Poles	2-Pole
Performance	<ul style="list-style-type: none"> • Moisture resistance: UL Listed to 3R, 3RX, 4, 4X, wet and damp locations (portable outlet boxes) • UV resistance: All exposed materials are UV stabilized • Flammability: UL94V0 (boxes, covers, and plates)
Type	Duplex Receptacle
UPC	781786380332

Electrical Ratings

Amperage Rating	15 A
Voltage Rating	250 V
Voltage Rating Description	250 V

Conductor Related

Number Of Wires	3-Wire
Wire Size	#18 AWG to #10 AWG

Certifications and Compliance

Industry Standard(s)	<ul style="list-style-type: none"> • IP69K in use • Listed to UL498 • Certified to CSA C22.2 No. 42 • Meets NEMA® WD-1, WD-6, and ANSI Standards • IP66 Suitability • NSF Certified (plugs, connectors and receptacles)
Nema Rating	L6-15R

Product Assets

[Catalog Page - Bryant I-5 Catalog page](#)
[Catalogs - Bryant Full Line Catalog](#)

Related Products

- [BRY60CM84AK - Watertight Series, Adapter Kit, 1" NPT, Yellow](#)
- [BRY60CM83AK - Watertight Series, FD Box, 3/4" NPT, Gray](#)
- [BRY60CM88 - Weatherproof Boxes, 1-Gang, Blank Plate, FS/FD Style, Yellow](#)
- [BRY6083AK - Watertight Series, Adapter Kit, 3/4" NPT, Gray](#)
- [BRY6084 - Watertight Series, FD Box, 1" NPT, Gray](#)



A proud member of the Hubbell Family.