




Straight Blade Devices, Receptacles, Duplex, Commercial Grade, 20A 125V, 2-Pole 3-Wire Grounding, 5-20R, Gray, Single Pack

By Bryant
Catalog # [CRS20GRY](#)

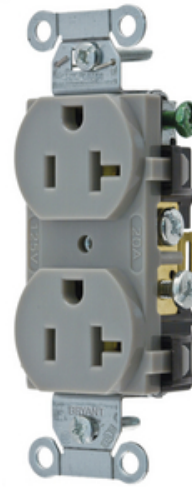

Straight Blade Devices, Receptacles, Duplex, Commercial
Grade, 20A 125V, 2-Pole 3-Wire Grounding, 5-20R, Gray, Single
Pack

Application

Commercial Specification Grade

General

Color	Gray
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Item Type	Traditional Duplex Smooth Face
Material	Composite
Material - Mounting Hardware	Screw Mounting
Number Of Poles	2-Pole
OEM Brand Name	Hubbell Bryant
Series	Commercial
Style	Smooth Face
Type	Duplex Receptacle
UPC	781786161061

Dimensions

Dimensions	3.28 in x 1.38 in x 1.07 in
Display Size	Standard Sized Product
Height	1.07 in
Length	3.28 in
Weight	0.2 lb
Width	1.38 in

Electrical Ratings

Amperage Rating	20 A
Connectivity	Side Wired Only
Current / Amperage Rating	20 A
Current Rating	20 A
Phase	Single Phase
Voltage Rating	125 V
Voltage Rating Description	125 V
Wattage	2500

Conductor Related

Number Of Wires	3-Wire
Wire Size	#14 AWG to #12 AWG

Certifications and Compliance

Nema Rating	5-20R
-------------	-------

Logistics

Carton Quantity	10
-----------------	----

Product Assets

[Catalog Page - Bryant A-12 Catalog page](#)
[Catalogs - Bryant Full Line Catalog](#)
[Literature - General Literature - Commercial Grade
Receptacles and Switches](#)
[Literature - General Literature - BRYANT® Wiring Devices](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
BRY-CRS20GRY-SPEC-EN | REV 7/2023