


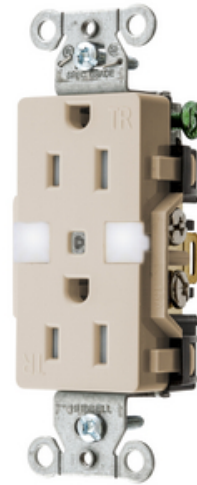

Straight Blade Devices, Receptacle, Tamper Resistant Decorator Duplex, Commercial Grade, 15A 125V, 2-Pole 3- Wire Grounding, 5-15R, With Night Light

By Bryant
Catalog # [DR15NLLA](#)

Straight Blade Devices, Receptacle, Tamper Resistant Decorator Duplex, Commercial Grade, 15A 125V, 2-Pole 3- Wire Grounding, 5-15R, With Night Light, Light Almond.



Features

- LED light activated when low levels of ambient light are detected by photosensor
- Tamper-resistant shutter complies with national electrical code
- Aesthetic Style Line® decorator design

Application

Commercial Specification Grade

General

Color	Light Almond
Horsepower - Maximum	0.5
Item Type	Decorator Duplex
Material	Nylon
Material - Mounting Hardware	Screw Mounting
Number Of Poles	2-Pole
Operating Temperature	Maximum continuous 75°C and minimum -40°C without Impact

Performance	<ul style="list-style-type: none">• Electrical - Color Temperature - 3400K - 3600K• Electrical - Dielectric Voltage - Withstands 2,000V minimum• Electrical - LED Energy Consumed - 0.5 watt• Electrical - Light Output - 0.5 Lumens• Electrical - Rating - 15A, 125VAC Only• Environmental - Flammability - UL 94 V-2• Environmental - Operating Temperatures - Maximum continuous 75°C, minimum -40°C (w/o impact)• Mechanical - Product Identification - Ratings are a permanent part of the device• Mechanical - Terminal Accommodation - #14-#10
-------------	---

Dimensions

Dimensions	3.29 in x 1.15 in x 1.29 in
Display Size	Standard Sized Product
Height	1.29 in
Length	3.29 in
Weight	0.2 lb
Width	1.15 in

Electrical Ratings

Amperage Rating	15 A
Connectivity	Back and Side Wired
Current / Amperage Rating	15 A
Current Rating	15 A
Dielectric Strength	Withstands 2,000V minimum
Voltage Rating	125 V
Voltage Rating Description	125 V
Wattage	1875 W

Conductor Related

Number Of Wires	3-Wire
Wire Size	#14 AWG to #10 AWG

Certifications and Compliance

Industry Standard(s)	<ul style="list-style-type: none">• Certified to CSA, C22.2, No. 42• NEMA® WD-6 Compliant• UL Listed to UL498 File No. E2186
Nema Rating	5-15R

Logistics

Carton Quantity	10
-----------------	----

Product Assets

[Catalog Page - Bryant A-18 Catalog page](#)
[Catalogs - Bryant Full Line Catalog](#)
[Literature - Residential Catalog](#)

AWG copper stranded or solid conductor only

- Mechanical - Terminal Identification - Terminals identified in accordance with UL 498 and CSA

Series	Commercial Specification Grade
Style	Style Line Decorator
Type	Nightlight
UPC	783585541327



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
BRY-DRI5NLLA-SPEC-EN | REV 7/2023