


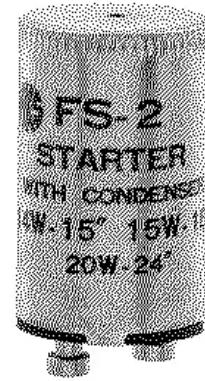

Lampholders, Fluorescent Starter, 14-15-20W

By Bryant
Catalog # FS2A



Lampholders, Fluorescent Starter, 14-15-20W

Features

14-15-20W

Application

Low Wattage Fluorescent

General

Catalog Number	FS2A
Color	White
EU RoHS Indicator	No
Item Type	Fluorescent Starters
Lamp Type	Pre-Heat
Material - Mounting Hardware	Plug-In
Minimum Starting Temperature	40 Degrees F °
OEM Brand Name	Hubbell Bryant
Series	Fluorescent Starters

Start Type	Neo-Start
Type	Neostart
UPC	781786689701

Electrical Ratings

Frequency Rating	60 Hz
Voltage Rating	120/277V AC kV
Wattage	14, 15, 20W

Logistics

Carton Quantity	25
-----------------	----

Product Assets

[Catalog Page - BRY O-6 Catalog Page](#)
[Catalogs - Bryant Full Line Catalog](#)
[Specifications - FS2A](#)