




# Lampholders, Fluorescent Starter, 13-30-40W

By Bryant  
Catalog # FS4A

Lampholders, Fluorescent Starter, 13-30-40W

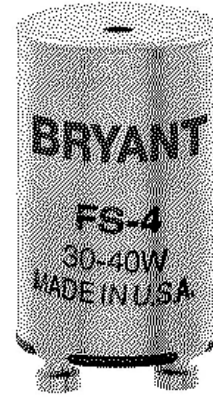

## Features

13-30-40W

## Application

Low Wattage Fluorescent

## General

Catalog Number	FS4A
Color	White
EU RoHS Indicator	No
Item Type	Fluorescent Starters
Lamp Type	Pre-Heat
Material - Mounting Hardware	Plug-In
Minimum Starting Temperature	40 Degrees F °
OEM Brand Name	Hubbell Bryant
Series	Fluorescent Starters

Start Type	Neo-Start
Type	Neostart
UPC	781786689725

## Electrical Ratings

Frequency Rating	60 Hz
Voltage Rating	120/277V AC kV
Wattage	13, 30, 40W

## Logistics

Carton Quantity	25
-----------------	----

## Product Assets

[Catalog Page - BRY O-6 Catalog Page](#)  
[Catalogs - Bryant Full Line Catalog](#)  
[Specifications - FS4A](#)