


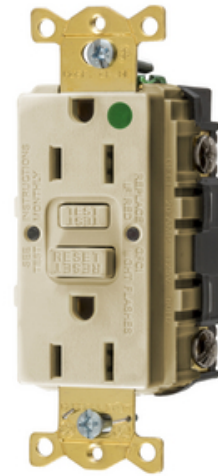

Power Protection Products, GFCI Receptacles, Self Test, Hospital Grade, 15A 125V, 2-Pole 3-Wire Grounding, 5-15R, Ivory

By Bryant
Catalog # [GFST82I](#)

Power Protection Products, GFCI Receptacles, Self Test, Hospital Grade, 15A 125V, 2-Pole 3-Wire Grounding, 5-15R, Ivory



General

Color	Ivory
Number Of Poles	2-Pole
Series	Hospital Grade
Style	Standard
Type	Heavy Duty
UPC	781786150133

Electrical Ratings

Amperage Rating	20 A
Current / Amperage Rating	20 A
Voltage Rating	125 V
Voltage Rating Description	125 V

Conductor Related

Number Of Wires	3-Wire
-----------------	--------

Certifications and Compliance

Nema Rating	5-20R
-------------	-------

Logistics

Carton Quantity	10
-----------------	----

Product Assets

[Catalog Page - Bryant B-7 Catalog page](#)
[Catalog Page - Bryant C-4 Catalog page](#)
[Catalogs - Bryant Full Line Catalog](#)
[Literature - CIRCUITPRO® Self Test GFCI](#)
[Literature - 2015 UL GFCI Requirements](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
BRY-GFST82I-SPEC-EN | REV 7/2023