




# 15A COMM HG SELF TEST TR ALARM GFR IVORY

By Bryant  
Catalog # [GFST82ITRB](#)

15A COMM HG SELF TEST TR ALARM GFR IVORY

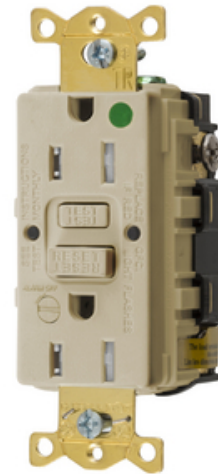

## General

Color	Ivory
Number Of Poles	2-Pole
Series	Hospital Grade
Style	Tamper-Resistant
Type	Heavy Duty
UPC	781786390195

## Electrical Ratings

Amperage Rating	15 A
Current / Amperage Rating	15 A
Voltage Rating	125 V
Voltage Rating Description	125 V

## Conductor Related

Number Of Wires	3-Wire
-----------------	--------

## Certifications and Compliance

Nema Rating	5-15R
-------------	-------

## Logistics

Carton Quantity	25
-----------------	----

## Product Assets

[Catalog Page - Bryant C-3 Catalog page](#)  
[Catalog Page - Bryant B-7 Catalog page](#)  
[Catalogs - Bryant Full Line Catalog](#)  
[Literature - CIRCUITPRO® Self Test GFCI](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.  
BRY-GFST82ITRB-SPEC-EN | REV 7/2023