


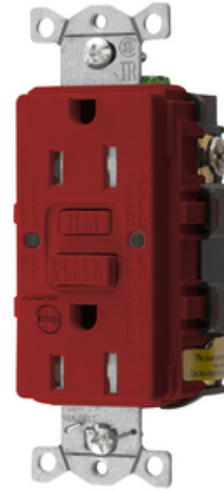

Power Protection Products, GFCI Receptacle, Self Test, Commercial Grade, Tamper Resistant, 15A 125V, 2- Pole 3-Wire Grounding, 5-15R, With Alarm, Red

By Bryant
Catalog # [GFTRST15RB](#)

Power Protection Products, GFCI Receptacle, Self Test, Commercial Grade, Tamper Resistant, 15A 125V, 2- Pole 3-Wire Grounding, 5-15R, With Alarm, Red



Features

- Patented shutter design for tamper-resistant
- Compliant with NEC® 406.12 and NEC® 517-18(c)
- Patented AUTOGUARD® self test technology
- Triple wipe construction
- Alarm version provides audible notification of a trip condition

General

Color	<ul style="list-style-type: none">• Red• Rouge
EU RoHS Indicator	Contact Manufacturer
Series	Heavy Duty
Style	Alarm
Type	Tamper-Resistant
UPC	883778228223

Electrical Ratings

Amperage Rating	15 A
Current / Amperage Rating	15 A
Voltage Rating Description	125 V

Certifications and Compliance

Nema Rating	5-15R
-------------	-------

Logistics

Carton Quantity	10
-----------------	----

Product Assets

[Catalog Page - Bryant C-3 Catalog page](#)
[Catalogs - Bryant Full Line Catalog](#)
[Literature - CIRCUITPRO® Self Test GFCI](#)
[Literature - 2015 UL GFCI Requirements](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
BRY-GFTRST15RB-SPEC-EN | REV 7/2023