




Power Protection Products, Receptacles, GFCI, Commercial Grade, Self Test, 20A 125V, 2-Pole 3-Wire Grounding, 5- 20R, With Nightlight, Ivory

By Bryant
Catalog # [GFTRST20INL](#)

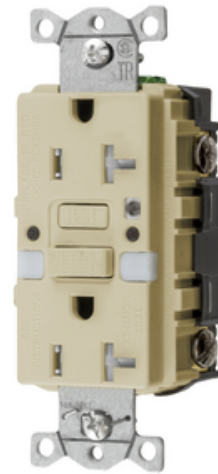

Power Protection Products, Receptacles, GFCI, Commercial Grade, Self Test, 20A 125V, 2-Pole 3-Wire Grounding, 5- 20R, With Nightlight, Ivory

Features

- Patented shutter design for tamper-resistant
- Compliant with NEC® 406.12 and NEC® 517-18(c)
- Patented AUTOGUARD® self test technology
- Triple wipe construction

General

Color	<ul style="list-style-type: none"> • Ivory • Ivoire
EU RoHS Indicator	Contact Manufacturer
Series	Heavy Duty
Style	Nightlight
Type	<ul style="list-style-type: none"> • Tamper-Resistant • Tamper-Resistant
UPC	883778123474

Electrical Ratings

Amperage Rating	20 A
Current / Amperage Rating	20 A
Voltage Rating Description	125 V

Certifications and Compliance

Industry Standard(s)	Meets All NEC® Requirements
Nema Rating	5-20R

Logistics

Carton Quantity	10
-----------------	----

Product Assets

- [Catalog Page - WDK K-4 Catalog Page](#)
- [Catalog Page - WDK Z-8 Catalog Page](#)
- [Catalogs - Wiring Device-Kellems Full Catalog](#)
- [Catalogs - Bryant Full Line Catalog](#)
- [Literature - CIRCUITPRO® Self Test GFCI](#)
- [Literature - 2015 UL GFCI Requirements](#)
- [Literature - AUTOGUARD® Self Test Ground Fault Receptacles](#)
- [Literature - Residential Catalog](#)
- [Sales Drawings - WDK_GFTRST20INL_DRAWINGS_PDF](#)



A proud member of the Hubbell Family.