




Power Protection Products, Receptacles, GFCI, Commercial Grade, Self Test, 20A 125V, 2-Pole 3-Wire Grounding, 5- 20R, With Nightlight, Red

By Bryant
Catalog # [GFTRST20RNL](#)

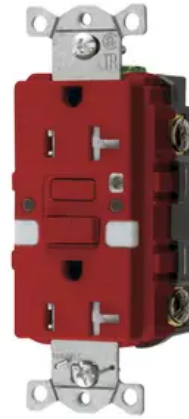

GFCI, Commercial Grade, Self Test, 20A 125V, 2-Pole 3-Wire
Grounding, 5-20R, with Nightlight

General

Catalog Number	GFTRST20RNL
Color	Red
EU RoHS Indicator	Contact Manufacturer
Series	Heavy Duty
Specifications	<ul style="list-style-type: none"> • Base - Nylon • Face - Nylon • Ground Contacts - Brass • Mounting Screws - Zinc plated steel • Mounting Strap - Zinc plated steel • Power Contacts - Brass
Style	Nightlight
Type	Tamper-Resistant
UPC	883778123504

Electrical Ratings

Amperage Rating	20 A
-----------------	------

Current / Amperage Rating	20 A
Voltage Rating Description	125 V

Certifications And Compliance

Industry Standard(s)	Meets All NEC® Requirements
Nema Rating	5-20R

Logistics

Carton Quantity	10
-----------------	----

Product Assets

- [Catalog Page - WDK Z-8 Catalog Page](#)
- [Catalog Page - WDK K-4 Catalog Page](#)
- [Catalogs - WDK Catalog Full 2024](#)
- [Literature - 2015 UL GFCI Requirements](#)
- [Literature - CIRCUITPRO® Self Test GFCI](#)
- [Sales Drawings - WDK_GFTRST20RNL_DRAWINGS_PDF](#)
- [Specifications - GFTRST20RNL](#)