




Power Protection Devices, Receptacle, Self Test, GFCI, Commercial Grade, 20A 125V, 2- Pole 3-Wire Grounding, 5- 20R, Almond

By Bryant
Catalog # [GFTWRST20AL](#)

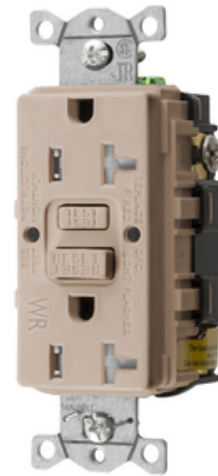

Power Protection Devices, Receptacle, Self Test, GFCI,
Commercial Grade, 20A 125V, 2-Pole 3-Wire Grounding, 5-
20R, Almond

Features

- Patented shutter design for tamper-resistant protection
- Meets NEC requirements for TR (517-18c) and WR (406.9), UV and corrosion resistance for harsh and damp applications
- Patented AUTOGUARD® self test technology
- Protects against line and load reversal, no power to the face or downstream if device is miswired

General

Color	Almond
EU RoHS Indicator	Contact Manufacturer
Series	Heavy Duty
Style	Standard
Type	Tamper-Resistant, Weather Resistant
UPC	883778122644

Electrical Ratings

Amperage Rating	20 A
Current / Amperage Rating	20 A
Voltage Rating Description	125 V

Certifications and Compliance

Industry Standard(s)	Meets All NEC® Requirements
Nema Rating	5-20R

Logistics

Carton Quantity	10
-----------------	----

Product Assets

[Catalog Page - WDK Z-8 Catalog Page](#)
[Catalogs - Wiring Device-Kellems Full Catalog](#)
[Literature - CIRCUITPRO® Self Test GFCI](#)
[Literature - 2015 UL GFCI Requirements](#)
[Literature - Education Application Guide](#)
[Sales Drawings - WDK_GFTWRST20_DRAWINGS_PDF](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
BRY-GFTWRST20AL-SPEC-EN | REV 7/2023