




Single Pole Products, Tapping Tee, 150 Amp Series, Blue

By Bryant
Catalog # [HBL15TBL](#)

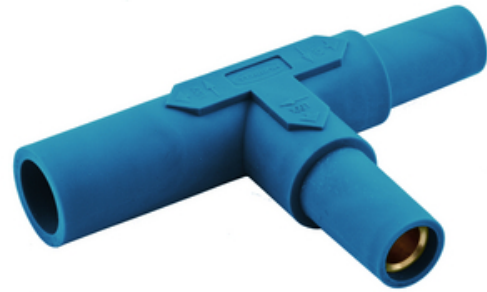

Single Pole Products, Tapping Tee, 150 Amp Series, Blue

Application

Temporary Electrical Power

General

Color	Blue
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Insulation	Insulated Body
Item Type	Tapping Tee
Material	Brass and Non-Metallic
Material - Mounting Hardware	Cord Mounted
Number Of Poles	1-Pole
Series	Series 15
Style	Tapping Tee Female-Female-Male
Temperature Rating	Maximum Continuous: 75° C; Minimum Continuous: -40° C w/o impact, -25° with impact.
Type	Tee
UPC	783585458632

Dimensions

Display Size	Standard
--------------	----------

Electrical Ratings

Amperage Rating	150 A
Connectivity	Plug-In
Current / Amperage Rating	150 A
Current Rating	150 A
Voltage Rating Description	600V AC/DC

Conductor Related

Number Of Conductors	1 Conductor
----------------------	-------------

Certifications and Compliance

Industry Standard(s)	<ul style="list-style-type: none">National Electric Code (NEC), ANSI/NFPA 70UL and cUL ListedUL Enclosure Types 3R, 4X, 12
Nema Rating	Non-NEMA

Logistics

Carton Quantity	25
-----------------	----

Product Assets

[Catalog Page - Bryant L-4 Catalog page](#)
[Catalogs - Bryant Full Line Catalog](#)
[Literature - Single Pole Devices](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
BRY-HBL15TBL-SPEC-EN | REV 7/2023