




Heavy Duty Products, Single Pole Devices, Industrial Grade, Male to 6) Females, Distribution Block, 400A 600V AC/DC, Single Conductor, Pre-Wired

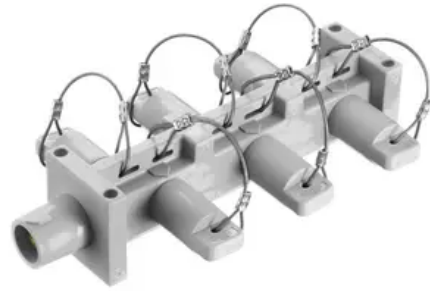

By Bryant
Catalog # [HBL7DBW](#)

Heavy Duty Products, Single Pole Devices, Industrial Grade, Male to 6) Females, Distribution Block, 400A 600V AC/DC, Single Conductor, Pre-Wired, White

Features

- Industrial Grade
- Male to 6) Females
- Distribution Block

Application

High Ampacity

Performance

- Electrical - Amperage Rating - 400A Maximum
- Electrical - Voltage Ratings - 600V AC Maximum
- 250V DC Maximum
- Mechanical - Product Identification - Ratings are a permanent part of the device

General

Catalog Number	HBL7DBW
Color	White
EU RoHS Indicator	Contact Manufacturer
Insulation	Insulated Body
Item Type	Distribution Block
Material	Brass and Elastomer
Number Of Pins	1) In, 6) Out- Male 6) Female
Operating Temperature	Max Continuous- 75 Degrees C, Minimum- -40 Without Impact

Series Specifications

Series 16
• Body Material - Thermoplastic Elastomer
• Contact Material - Brass
• Product Type - Distribution Block
1-Male, 6-Female
Distribution Block
783585112398

Style Type UPC

Electrical Ratings

Amperage Rating	400 A
Current / Amperage Rating	400 A
Current Rating	400 A
Voltage Rating Description	600V AC/DC
Wattage	360000

Certifications And Compliance

Industry Standard(s)	UL 498 And UL1691
----------------------	-------------------

Product Assets

- [Catalog Page - WDK H-8 Catalog Page](#)
- [Catalogs - WDK Catalog Full 2024](#)
- [Catalogs - Bryant Full Line Catalog](#)
- [Literature - Single Pole Devices](#)
- [Specifications - HBL7DBW](#)